
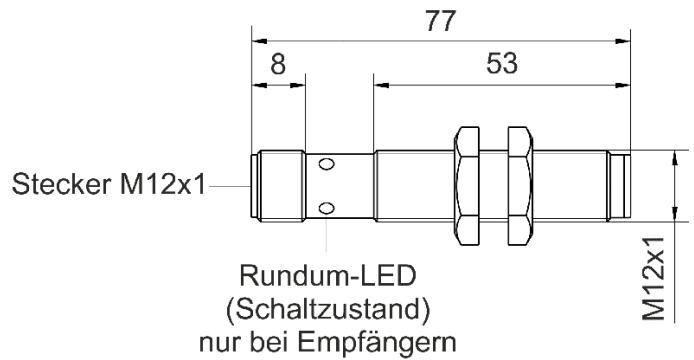


[Article Page](#)

Product Description

reflex light probe

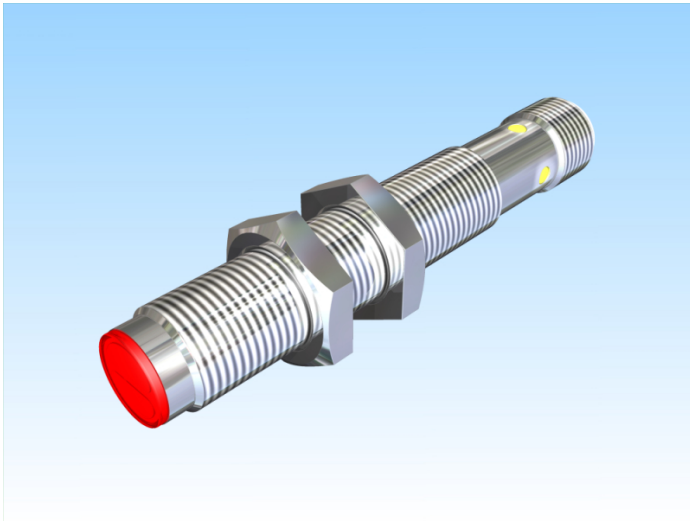

Name
Order number
Switching distance
Switch type

KORT200-M12MB73-DPA-V2-IR
08361245127
from 200 mm to 200 mm


 Changeover
PNP

 Infrared light 880 nm

Signal Type
Illuminant
Connection

 Connector

Connection diagramm

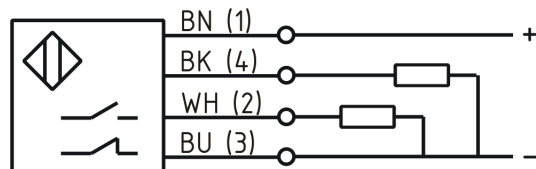

M12 x 75

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Termination

Diffuse mode sensor

10 - 30 V DC

150 mA

< 30 mA

500 Hz

-25 ° C to 70 ° C

LED

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361245127](#)