
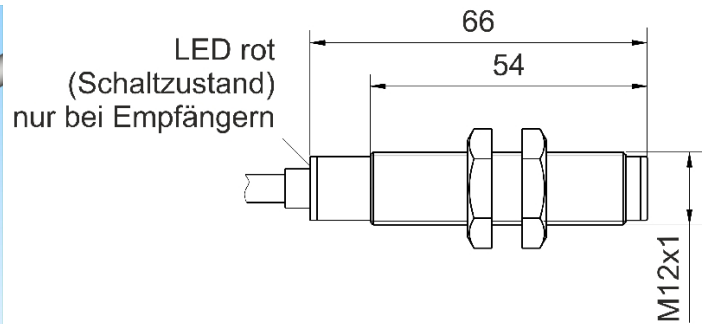


[Article Page](#)

Product Description

reflex light probe

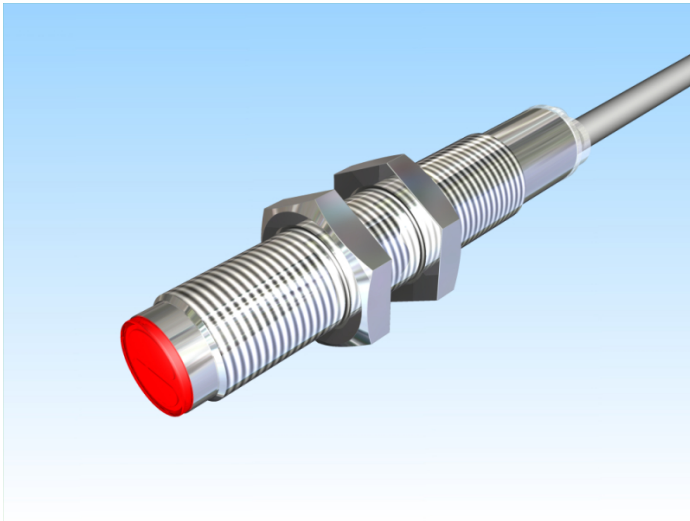

 
Name
Order number
Switching distance
Switch type

KORT400-M12MB64-DPÖ-IR
08361245223
from 400 mm to 400 mm


Signal Type
Illuminant
Connection

 N.C.
PNP
 Infrared light 880 nm

Connection diagramm

 Cable

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Switching state
Sensitivity adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Termination

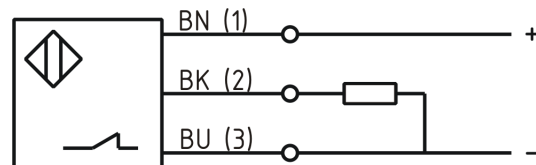

M12 x 64

Diffuse mode sensor
10 - 30 V DC
150 mA
< 30 mA
200 Hz
-25 ° C to 70 ° C
LED
ja
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
2m PVC 4x0,14mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361245223](#)