

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switching distance

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

reflex light probe

KORT500-M18MB71-DPU-IR

08361250219

M18B-D0500P-CX9C4U2

500 mm

100110




Programmable

DC PNP

IR Infrared light 880 nm



Cable

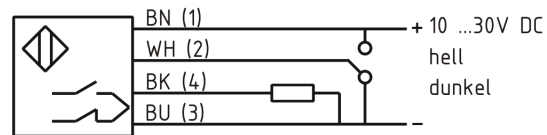

M18 x 71

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Switching state

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Termination

Diffuse mode sensor

10 - 30 V DC

200 mA

< 30 mA

300

-25 ° C to 55 ° C

LED

ja

nein

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

2m PVC 4x0,5mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361250219](#)