

Material:
• Polystyrene
Seal:
• Neoprene

Characteristics:
• Hexagon base
• PG Thread




once according to DIN 46320

Outer thread	Clamping range mm	Cat. No. Lt. Gray	Std. Pk.
PG			
PG 7	3.5 - 6	5202078	50
PG 9	4.5 - 7	5202094	50
PG 11	6 - 9	5202116	50
PG 13.5	9 - 12	5202132	50
PG 16	11 - 14	5202167	50
PG 21	14 - 18	5202213	20
PG 29	18 - 25	5202299	10
PG 36	25 - 32	5202361	10
PG 42	30 - 38	5202434	10
PG 48	36 - 44	5202485	10



Temperature Range
-20 to 100°C
(-4 to 212°F)

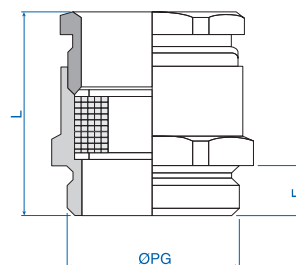

Dimensions		
Thread Size	E mm	L mm
PG7	8	29
PG9	8	31.5
PG11	8	33
PG13.5	9.5	36
PG16	10	40.5
PG21	11	43.5
PG29	11	46
PG36	13	57
PG42	13	61
PG48	14	60

Locknuts and seal rings sold separately, see page 24 and 35.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[5202132](#) [5202361](#) [5202116](#) [5202485](#) [5202299](#) [5202078](#) [5202213](#) [5202167](#) [5202434](#) [5202094](#)