

**Material:**

- Nickel-plated brass


**Characteristics:**

- Metric external thread
- PG internal thread
- Hexagon

| External thread      | Internal thread | SW mm | Thread length mm | Complete length mm | Cat. No. | Std. Pk. |
|----------------------|-----------------|-------|------------------|--------------------|----------|----------|
| <b>Metric Form A</b> | <b>PG</b>       |       |                  |                    |          |          |
| M 12 x 1.5           | PG 7            | 14    | 7                | 17                 | 6604712  | 100      |
| M 16 x 1.5           | PG 9            | 18    | 7                | 17.5               | 6604716  | 50       |
| M 16 x 1.5           | PG 11           | 20    | 7                | 18                 | 6604715  | 50       |
| M 16 x 1.5           | PG 13.5         | 22    | 7                | 19.5               | 6604709  | 50       |
| M 20 x 1.5           | PG 11           | 22    | 7                | 18                 | 6604720  | 50       |
| M 20 x 1.5           | PG 13.5         | 22    | 7                | 19.5               | 6604721  | 50       |
| M 20 x 1.5           | PG 16           | 24    | 7                | 20.5               | 6604722  | 50       |
| M 20 x 1.5           | PG 21           | 32    | 7                | 22.5               | 6604708  | 50       |
| M 25 x 1.5           | PG 16           | 27    | 8                | 21.5               | 6604726  | 50       |
| M 25 x 1.5           | PG 21           | 32    | 8                | 23.0               | 6604725  | 50       |
| M 25 x 1.5           | PG 29           | 40    | 8                | 25                 | 6604727  | 20       |
| M 32 x 1.5           | PG 21           | 34    | 8.5              | 23.5               | 6604729  | 20       |
| M 32 x 1.5           | PG 29           | 40    | 8.5              | 25.0               | 6604732  | 10       |
| M 50 x 1.5           | PG 36           | 52    | 9.5              | 29                 | 6604742  | 10       |
| M 50 x 1.5           | PG 42           | 58    | 9.5              | 31.5               | 6604750  | 5        |
| M 63 x 1.5           | PG 48           | 65    | 10.5             | 32.5               | 6604763  | 1        |
| <b>Form B</b>        |                 |       |                  |                    |          |          |
| M 20 x 1.5           | PG 9            | 22    | 7                | 11                 | 6604719  | 50       |
| M 25 x 1.5           | PG 13.5         | 27    | 8                | 12                 | 6604724  | 50       |
| M 32 x 1.5           | PG 13.5         | 34    | 8.5              | 12.5               | 6604706  | 20       |
| M 32 x 1.5           | PG 16           | 34    | 8.5              | 12.5               | 6604728  | 20       |
| M 32 x 1.5           | PG 21           | 34    | 8.5              | 12.5               | 6604730  | 20       |
| M 40 x 1.5           | PG 16           | 42    | 8.5              | 13.5               | 6604705  | 10       |
| M 40 x 1.5           | PG 21           | 42    | 8.5              | 13.5               | 6604733  | 10       |
| M 40 x 1.5           | PG 29           | 42    | 8.5              | 13.5               | 6604735  | 20       |
| M 50 x 1.5           | PG 21           | 52    | 9.5              | 15.5               | 6604704  | 10       |



Form A

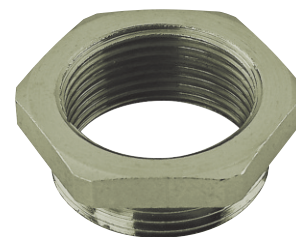

Form B

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[6402333](#) [6402332](#) [6402316](#) [6402326](#) [6402317](#) [6402325](#)