


2 PHASE BUSBAR - 1/2 pole spacing

18mm² for 80A / 25mm² for 100A

Altech Corp.®

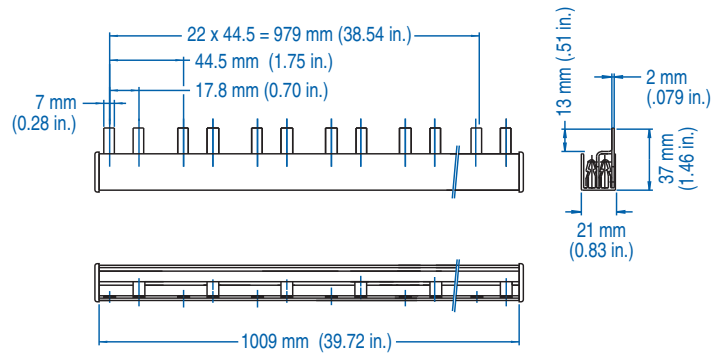

18mm² for 80A

Type/ Cat. No.	No. of Pins	No. of MMC to Jumper	Length [mm]
2P18U3H/4	4	2x2 pole	75.3
2P18U3H/6	6	3x2 pole	119.8
2P18U3H/8	8	4x2 pole	164.3
2P18U3H/10	10	5x2 poles	208.8
2P18U3H/12	12	6x2 pole	253.3
2P18U3H/14	14	7x2 pole	297.8
2P18U3H/16	16	8x2 pole	342.3
2P18U3H/18	18	9x2 pole	386.8
2P18U3H/20	20	10x2 pole	431.3
2P18U3H/22	22	11x2 pole	475.8
2P18U3H/24	24	12x2 pole	520.3
2P18U3H/26	26	13x2 pole	564.8
2P18U3H/28	28	14x2 pole	609.3
2P18U3H/30	30	15x2 pole	653.8
2P18U3H/32	32	16x2 pole	698.3
2P18U3H/34	34	17x2 pole	742.8
2P18U3H/36	36	18x2 pole	787.3
2P18U3H/38	38	19x2 pole	831.8
2P18U3H/40	40	20x2 pole	876.3
2P18U3H/42	42	21x2 pole	920.8
2P18U3H/44	44	22x2 pole	965.3
2P18U3H/46	46	23x2 pole	1009.8
2P18U3H/48	48	24x2 pole	1054.3
2P18U3H/50	50	25x2 pole	1098.8
2P18U3H/52	52	26x2 pole	1143.3
2P18U3H/54	54	27x2 pole	1187.8
2P18U3H/56	56	28x1 pole	1232.3

25mm² for 100A

Type/ Cat. No.	No. of Pins	No. of MMC to Jumper	Length [mm]
2P25U3H/4	4	2x2 pole	75.3
2P25U3H/6	6	3x2 pole	119.8
2P25U3H/8	8	4x2 pole	164.3
2P25U3H/10	10	5x2 pole	208.8
2P25U3H/12	12	6x2 pole	253.3
2P25U3H/14	14	7x2 pole	297.8
2P25U3H/16	16	8x2 pole	342.3
2P25U3H/18	18	9x2 pole	386.8
2P25U3H/20	20	10x2 pole	431.3
2P25U3H/22	22	11x2 pole	475.8
2P25U3H/24	24	12x2 pole	520.3
2P25U3H/26	26	13x2 pole	564.8
2P25U3H/28	28	14x2 pole	609.3
2P25U3H/30	30	15x2 pole	653.8
2P25U3H/32	32	16x2 pole	698.3
2P25U3H/34	34	17x2 pole	742.8
2P25U3H/36	36	18x2 pole	787.3
2P25U3H/38	38	19x2 pole	831.8
2P25U3H/40	40	20x2 pole	876.3
2P25U3H/42	42	21x2 pole	920.8
2P25U3H/44	44	22x2 pole	965.3
2P25U3H/46	46	23x2 pole	1009.8
2P25U3H/48	48	24x2 pole	1054.3
2P25U3H/50	50	25x2 pole	1098.8
2P25U3H/52	52	26x2 pole	1143.3
2P25U3H/54	54	27x2 pole	1187.8
2P25U3H/56	56	28x2 pole	1232.3

ACCESSORIES



Type/Cat. No.:	P50UT	P50UB	BRS5	18/25CAP3P
Description:	Power Feed Lug	Modular Direct Power Feed	Insulation Cap	End Cap

Altech UL1077

Altech UL508

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[2P18U3H/56](#) [2P18U3H/66](#) [2P18U3H/14](#) [2P18U3H/10](#) [2P18U3H/12](#) [2P18U3H/44](#) [2P25U3H/60](#) [2P25U3H/32](#)
[2P25U3H/54](#) [2P25U3H/40](#) [2P25U3H/6](#) [2P25U3H/58](#) [2P25U3H/50](#) [2P25U3H/52](#) [2P25U3H/14](#) [2P25U3H/28](#)
[2P25U3H/4](#) [2P25U3H/66](#) [2P25U3H/18](#) [2P25U3H/26](#) [2P25U3H/36](#) [2P18U3H/68](#) [2P25U3H/24](#) [2P25U3H/44](#)
[2P25U3H/64](#) [2P25U3H/20](#) [2P25U3H/16](#) [2P25U3H/42](#) [2P25U3H/10](#) [2P25U3H/34](#) [2P25U3H/38](#) [2P25U3H/68](#)
[2P25U3H/8](#) [2P18U3H/50](#) [2P18U3H/58](#) [2P25U3H/22](#) [2P18U3H/20](#) [2P18U3H/28](#) [2P18U3H/24](#) [2P18U3H/60](#)
[2P25U3H/48](#) [2P25U3H/62](#) [2P18U3H/40](#) [2P25U3H/56](#) [2P25U3H/12](#) [2P25U3H/30](#) [2P18U3H/36](#) [2P18U3H/46](#)
[2P18U3H/42](#) [2P18U3H/54](#) [2P25U3H/46](#) [2P18U3H/22](#) [2P18U3H/30](#) [2P18U3H/62](#) [2P18U3H/6](#) [2P18U3H/16](#)
[2P18U3H/18](#) [2P18U3H/38](#) [2P18U3H/64](#) [2P18U3H/34](#) [2P18U3H/4](#) [2P18U3H/8](#) [2P18U3H/48](#) [2P18U3H/52](#)
[2P18U3H/32](#) [2P18U3H/26](#)