
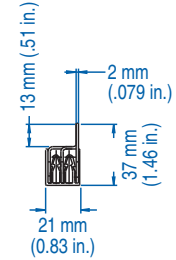


3 PHASE BUSBAR - 1/2 pole spacing

18mm² for 80A / 25mm² for 100A

Altech Corp.

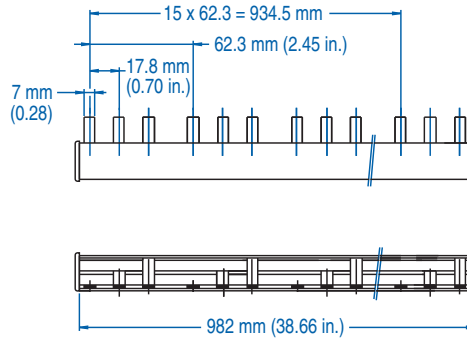


18mm² for 80A

Type/ Cat. No.	No. of Pins	No. of MMC to Jumper	Length [mm]
3P18U3H/6	6	2x3 pole	110.8
3P18U3H/9	9	3x3 pole	173.1
3P18U3H/12	12	4x3 pole	235.4
3P18U3H/15	15	5x3 pole	297.7
3P18U3H/18	18	6x3 pole	360.0
3P18U3H/21	21	7x3 pole	422.3
3P18U3H/24	24	8x3 pole	484.6
3P18U3H/27	27	9x3 pole	546.9
3P18U3H/30	30	10x3 pole	609.2
3P18U3H/33	33	11x3 pole	671.5
3P18U3H/36	36	12x3 pole	733.8
3P18U3H/39	39	13x3 pole	796.1
3P18U3H/42	42	14x3 pole	858.4
3P18U3H/45	45	15x3 pole	920.7
3P18U3H/48	48	16x3 pole	983.0
3P18U3H/51	51	17x3 pole	1045.3
3P18U3H/54	54	18x3 pole	1107.6
3P18U3H/57	57	19x3 pole	1169.9

25mm² for 100A

Type/ Cat. No.	No. of Pins	No. of MMC to Jumper	Length [mm]
3P25U3H/6	6	2x3 pole	110.8
3P25U3H/9	9	3x3 pole	173.1
3P25U3H/12	12	4x3 pole	235.4
3P25U3H/15	15	5x3 pole	297.7
3P25U3H/18	18	6x3 pole	360.0
3P25U3H/21	21	7x3 pole	422.3
3P25U3H/24	24	8x3 pole	484.6
3P25U3H/27	27	9x3 pole	546.9
3P25U3H/30	30	10x3 pole	609.2
3P25U3H/33	33	11x3 pole	671.5
3P25U3H/36	36	12x3 pole	733.8
3P25U3H/39	39	13x3 pole	796.1
3P25U3H/42	42	14x3 pole	858.4
3P25U3H/45	45	15x3 pole	920.7
3P25U3H/48	48	16x3 pole	983.0
3P25U3H/51	51	17x3 pole	1045.3
3P25U3H/54	54	18x3 pole	1107.6
3P25U3H/57	57	19x3 pole	1169.9

ACCESSORIES

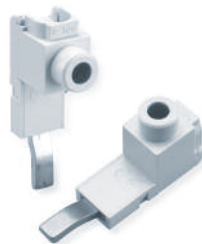

Type/Cat. No:

P50UT

Description:

Power Feed Lug



P50UB

Modular Direct Power Feed



Type/Cat. No:

BRS5

Description:

Insulation Cap



18/25CAP3P

End Cap

Altech UL1077

Altech UL508

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

<u>3P18U3H/30</u>	<u>3P18U3H/27</u>	<u>3P18U3H/72</u>	<u>3P18U3H/6</u>	<u>3P18U3H/60</u>	<u>3P25U3H/33</u>	<u>3P18U3H/33</u>	<u>3P25U3H/48</u>
<u>3P25U3H/18</u>	<u>3P25U3H/54</u>	<u>3P25U3H/72</u>	<u>3P18U3H/15</u>	<u>3P25U3H/27</u>	<u>3P25U3H/60</u>	<u>3P25U3H/66</u>	<u>3P25U3H/51</u>
<u>3P25U3H/30</u>	<u>3P25U3H/69</u>	<u>3P18U3H/57</u>	<u>3P25U3H/12</u>	<u>3P25U3H/36</u>	<u>3P25U3H/39</u>	<u>3P25U3H/42</u>	<u>3P18U3H/36</u>
<u>3P25U3H/21</u>	<u>3P18U3H/21</u>	<u>3P18U3H/63</u>	<u>3P18U3H/9</u>	<u>3P25U3H/11</u>	<u>3P18U3H/48</u>	<u>3P25U3H/57</u>	<u>3P18U3H/18</u>
<u>3P18U3H/66</u>	<u>3P25U3H/24</u>	<u>3P25U3H/63</u>	<u>3P25U3H/45</u>	<u>3P25U3H/6</u>	<u>3P25U3H/9</u>	<u>3P18U3H/24</u>	<u>3P25U3H/15</u>
<u>3P18U3H/39</u>	<u>3P18U3H/42</u>	<u>3P18U3H/54</u>	<u>3P18U3H/12</u>	<u>3P18U3H/45</u>	<u>3P18U3H/51</u>	<u>3P18U3H/69</u>	