

Panel Feed-through Blocks

Pin Spacing: 7.50mm
Orientation: Panel Mount
Clamp Type: Screw Cage
Design: Modular



MPT-275/ CMR-75

ELECTRICAL

	Current	Voltage	Wire Range
US	15A ^①	300V	30-14AWG
	24A	450V	2.5mm ² Stranded 4.0mm ² Solid

INSTALLATION DATA

Screw Size	M3	Panel Hole Size	5.2mm
Torque	0.5Nm (4.5 lbf-in.)	Stripping Lgth.	10.1mm


MATERIAL

Body	PA6.8	Screw	Galvanized Steel
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	125°C IEC	Clamp	Nickel Brass
Color	Green		

No. Poles	Cat. #	Length (B) (mm)	Std. Pk.
1	MPT-275	7.5	100

Retaining Key


2	CMR-752	14.8	50
3	CMR-753	22.3	50

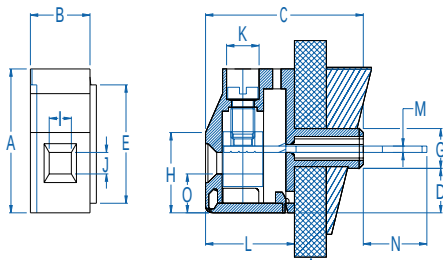

Wall Thickness <4.0 mm

Dimensions

A	18.10 mm	I	2.80 mm
B	7.50 mm	J	2.70 mm
C	19.85 mm	K	Ø4.10 mm
D	5.60 mm	L	11.20 mm
E	14.90 mm	M	0.80 mm
F	—	N	8.00 mm
G	Ø5.00 mm	O	4.90 mm
H	10.10 mm	P	—

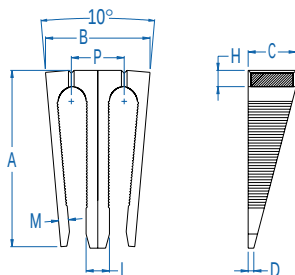

Dimensions

A	25.20 mm	I	—
B	14.80 mm	J	—
C	6.80 mm	K	—
D	0.80 mm	L	3.30 mm
E	—	M	1.40 mm
F	—	N	—
G	—	O	—
H	2.30 mm	P	7.50 mm

① 24A Factory Wiring - UL

Pin Spacing: 10.00mm
Orientation: Panel Mount
Clamp Type: Screw Cage
Design: Modular



MPT-410/ CMR-10

ELECTRICAL

	Current	Voltage	Wire Range
US	20A ^②	600V	30-12AWG
	32A	450V	4.0mm ² Stranded 6.0mm ² Solid

INSTALLATION DATA

Screw Size	M3	Panel Hole Size	8.2mm
Torque	0.5Nm (4.5 lbf-in.)	Stripping Lgth.	10.1mm


MATERIAL

Body	PA6.8	Screw	Galvanized Steel
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	125°C IEC	Clamp	Nickel Brass
Color	Green		

No. Poles	Cat. #	Length (B) (mm)	Std. Pk.
1	MPT-410	10.0	100

Retaining Key


2	CMR-102	19.8	50
3	CMR-103	29.3	50

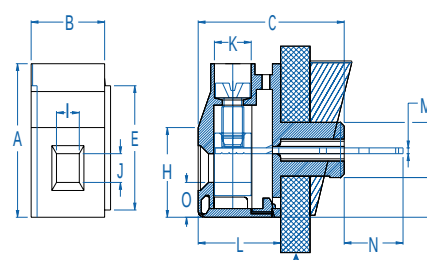

Wall Thickness <4.0 mm

Dimensions

A	20.90 mm	I	3.10 mm
B	10.00 mm	J	3.90 mm
C	19.85 mm	K	Ø5.00 mm
D	5.15 mm	L	11.20 mm
E	16.90 mm	M	0.80 mm
F	—	N	8.00 mm
G	Ø8.00 mm	O	4.75 mm
H	12.20 mm	P	—

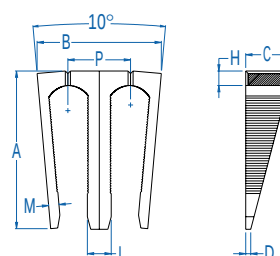

Dimensions

A	25.20 mm	I	—
B	19.80 mm	J	—
C	6.80 mm	K	—
D	0.80 mm	L	3.80 mm
E	—	M	1.65 mm
F	—	N	—
G	—	O	—
H	2.30 mm	P	10.00 mm

② 32A Factory Wiring - UL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CMR-103](#) [CMR-752](#) [CMR-753](#) [CMR-102](#)