
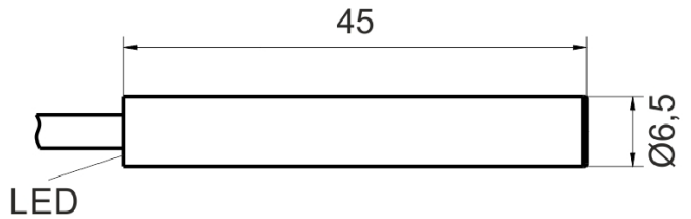


[Article Page](#)

Product Description

capacitive sensor DC

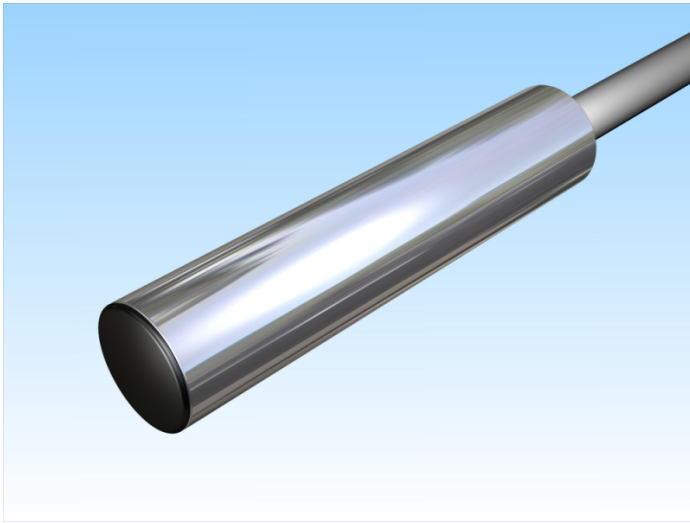


Name
Order number
Switching distance
Mounting

Switch type

Signal Type
Connection

Connection diagramm

SC1,5-G6,5MB45-DPS
08323650151
1,5 mm
 shielded
 N.O.
DC PNP
 Cable

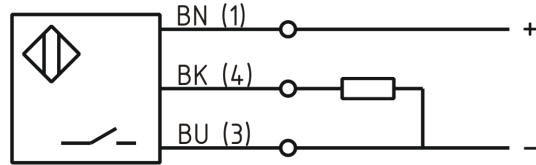

D 6.5 x 45

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Material active face

10 - 30 VDC
 $\leq 10 \%$
2 V
200 mA
 $\leq 10 \text{ mA}$
 $\leq 10 \mu\text{A}$
100
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED
ja
yes
yes
yes
IP67
DIN EN 60947-5-2: 2008
Brass, nickel plated
POM



SC1,5-G6,5MB45-DPS

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Cable length	2 m
Utilisation category	DC 13
Cable material	PVC grau LIYY
Cable cross	3x0.14 mm ²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08323650151](#)