
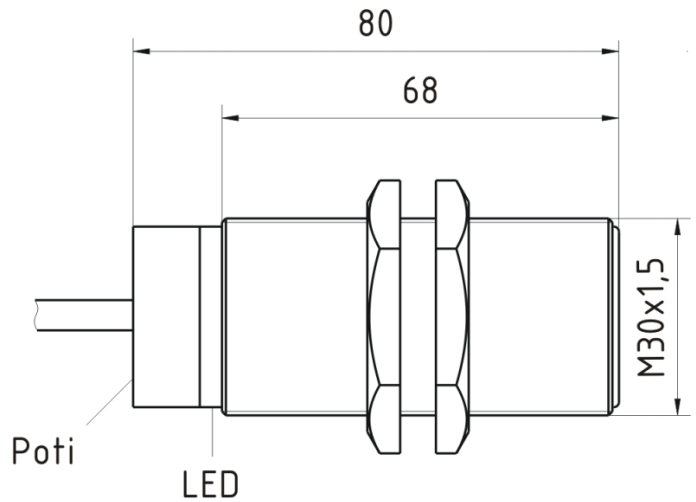


[Article Page](#)

Product Description

capacitive sensor AC/DC

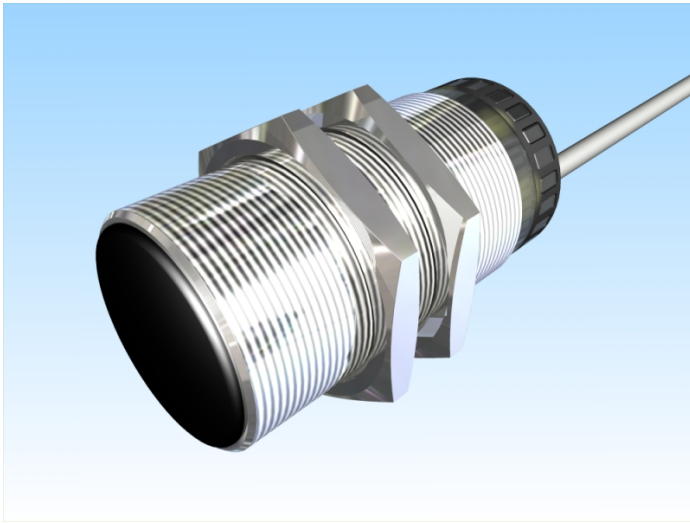

Name
Order number
Switching distance
Mounting


SC15-M30MB80-VZÖ
08323301580
15 mm

 shielded

 N.C.
AC/DC

 Cable

Connection diagramm

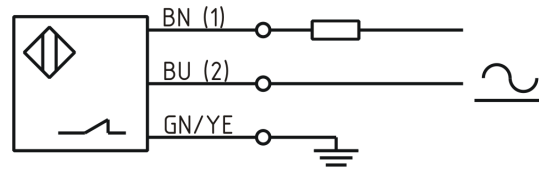

fine-pitch thread M30 x 80

Dimension (in mm)
Technical Specification
Operating voltage
Min. load current
Max. load current
Leakage current
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Material active face
Termination
Notes

20 - 250 V AC/DC
5 mA
200 mA
 $\leq 2,5$ mA
 ≤ 15 %
-25 ° C to 70 ° C
 $\leq 1-15$ %
 ≤ 1 %
LED
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
PBT
2m PVC 3x0,5mm²
Netzfrequenz: 50/60Hz Spannungsabfall: 10V DC /
8V AC Kurzzeitstrom: 2,2A (20ms) Max.
Schaltfrequenz: AC 25Hz / DC 40Hz



SC15-M30MB80-VZÖ

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08323301580](#)