

[Article Page](#)

Product Description
Name
Order number
Switching distance
Mounting

capacitive sensor DC
SC30-M30MN90-DPS-V2
08323303012
30 mm

 non shielded


Switch type

 N.O.
DC PNP

Signal Type
Connection

 Connector

Connection diagramm

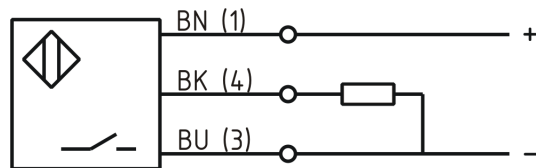

fine-pitch thread M30 x 90

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Digital output
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Material active face
Termination

10 - 30 VDC
 $\leq 10 \%$
2 V
200 mA
 $\leq 10 \text{ mA}$
 $\leq 10 \mu\text{A}$
100
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED

yes
yes
yes
IP67
DIN EN 60947-5-2:2008
PBT
Connector M12 4pol

Errors and omissions excepted

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08323303012](#)