

[Article Page](#)

Product Description
Name
Order number
Switching distance
Mounting

capacitive sensor DC
SC30-Q40KB-DPA-V2
08323443052
30 mm


Switch type

 shielded
 Changeover
DC PNP

Signal Type
Connection

 Connector

Connection diagramm

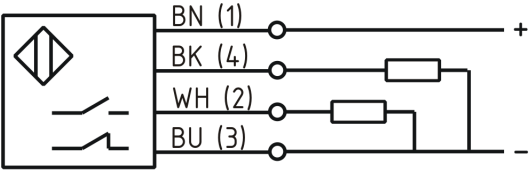

Q 40 x 40 x 120

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Digital output
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

10 - 30 VDC
 $\leq 10 \%$
2 V
300 mA
 $\leq 10 \text{ mA}$
 $\leq 10 \mu\text{A}$
100
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
LED
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
PBT
Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08323443052](#)