

[Article Page](#)

Product Description

Name

capacitive sensor DC

Order number


SC4-M12MB60-DPÖ

Switching distance

08323120420

Mounting

 4 mm



shielded

Switch type

 


N.C.

Signal Type


DC PNP

Connection



Cable

Connection diagramm

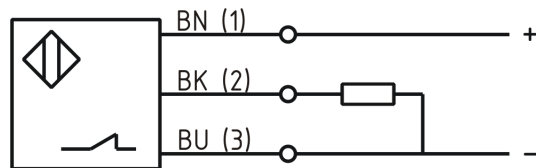

fine-pitch thread M12 x 60

Dimension (in mm)

Technical Specification

Operating voltage

10 - 30 V DC

Max. ripple

≤ 10 %

Voltage drop

2 V

Max. load current

200 mA

No load current

≤ 10 mA

Leakage current

≤ 10 µA

Switching frequency

100

Switching hysteresis

≤ 15 %

Operating temperature

-25 ° C to 70 ° C

Temperature drift

≤ 10 %

Repeat accuracy

≤ 5 %

Switching state

LED

Digital output

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Material active face

POM

Termination

2m PVC 3x0,34mm²

**Errors and omissions excepted**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08323120420](#)