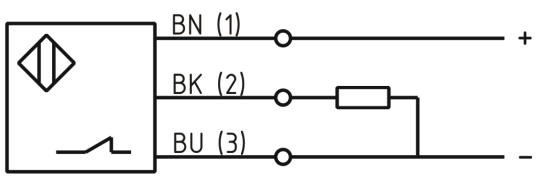


[Article Page](#)

Product Description		inductive speed limiter
Name	SJ15-M30MN80-DPÖI	
Order number	08343301520	
Switching distance	15 mm	
Mounting	 non shielded	
Switch type	 N.C.	
Signal Type	DC PNP	
Connection	 Cable	
Connection diagramm		

Technical Specification	
Operating voltage	10 - 30 V DC
Max. ripple	$\leq 10 \%$
Max. load current	200 mA
No load current	$\leq 30 \text{ mA}$
Leakage current	$\leq 10 \mu\text{A}$
Switching hysteresis	$\leq 15 \%$
Operating temperature	-25 ° C to 70 ° C
Temperature drift	$\leq 10 \%$
Repeat accuracy	1,0 %
Switching state	LED
Digital output	
Short-circuit proof	yes
Overload protection	yes
Reverse voltage protection	yes
Protection category	IP67
Material active face	PBT
Termination	2m PVC 3x0,5mm ²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08343301520](#)