



[Article Page](#)

Product Description

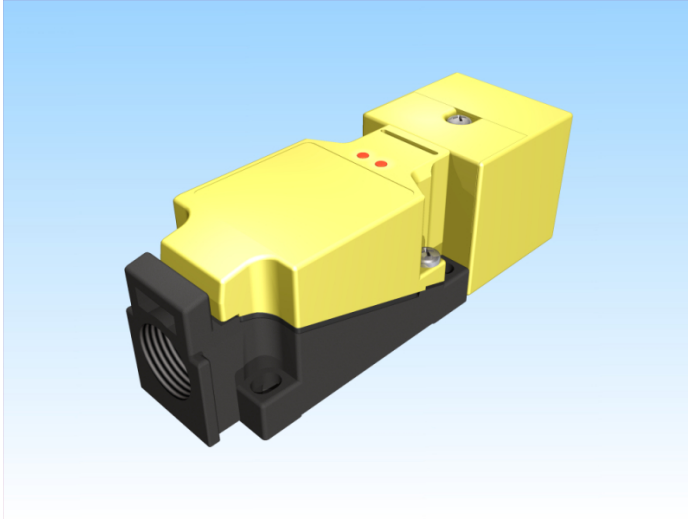

inductive sensor DC

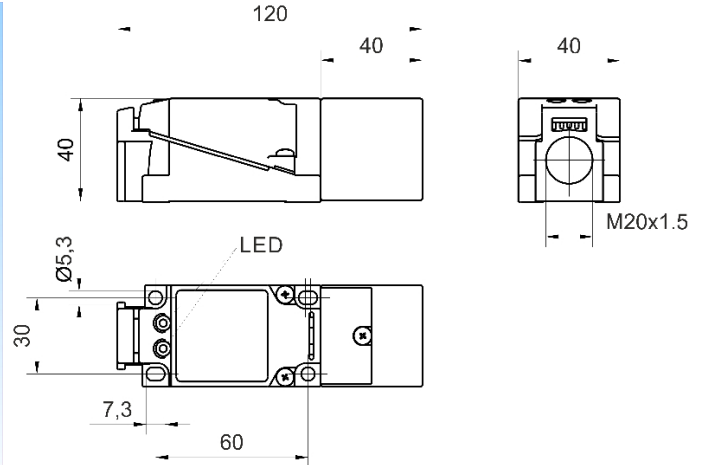

Name

SJ20-Q40KN-ANUI

Order number

08313204010

Switching distance

from 10 mm to 20 mm

Mounting



non shielded

Switch type



analog


Signal Type

Analog Current/Voltage

Connection

Terminal

Connection diagramm

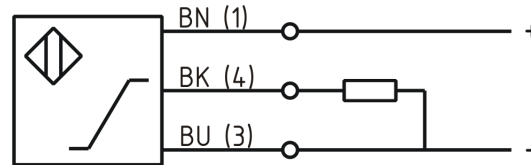

Dimension (in mm)

Q 40 x 40 x 120

Technical Specification

Special features

Output Voltage 0 ... 10 Volt

Output Current 0 ... 20 mA

18 - 30 V DC

$\leq 10 \%$

30 Hz

$\pm 5 \%$

$< 0,02 \%$

10 %

500 ms

IP67

DIN EN 60947-5-7:2004-06

PBT

DC 13

24 V DC

Terminal 1,5mm²

PBT Resin

Operating voltage

Max. ripple

Switching frequency

Temperature drift

Repeat accuracy

Linearity

Time delay

Protection category

EMC-level

Housing material

Utilisation category

Nominal operating voltage

Termination

Housing Material

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313204010](#)