

Name
Order number
Switching distance
Mounting

Switch type

Signal Type
Connection


Connection diagramm

SJ4-M18MB80-ANUI
08313180410
from 1 mm to 4 mm

 shielded

 analog
Analog Current/Voltage

 Cable

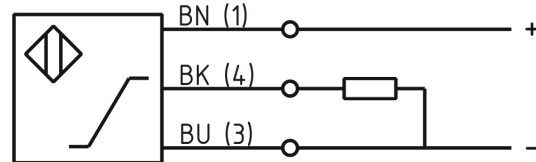

fine-pitch thread M18 x 80

Dimension (in mm)
Technical Specification
Special features

Output Voltage 0 ... 10 Volt
Output Current 0 ... 20 mA
18 - 30 VDC

≤ 10 %

≤ 15 mA

100 Hz

+/- 5 %

< 0,02 %

≤ 10 %

Pulso_has-1

300 ms

IP67

DIN EN 60947-5-7:2004-06

Brass, nickel plated

PBT

2 m

DC 13

PVC LIYY grau (grey)

24 V DC

4x0.5 mm²

Operating voltage
Max. ripple
No load current
Switching frequency
Temperature drift
Repeat accuracy
Linearity
Analog output
Time delay
Protection category
EMC-level
Housing material
Material active face
Cable length
Utilisation category
Cable material
Nominal operating voltage
Cable cross



SJ4-M18MB80-ANUI

Pulsotronic GmbH & Co. KG Neue Schichtstraße 14b 09366 Niederdorf Deutschland +49 (0)37296 930-200

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313180410](#)