

[Article Page](#)

Product Description
Name
Order number
Switching distance
Mounting

inductive sensor DC
SJ4-Q15KN32-DNS
08313150430
4 mm

 non shielded


Switch type

 N.O.
DC NPN

Signal Type
Connection

 Cable

Connection diagramm

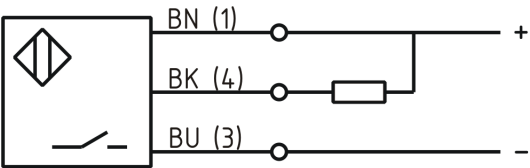

Q 15 x 8 x 35

Dimension (in mm)
Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Cable length
Utilisation category
Cable material
Cable cross

10 - 30 V DC
≤ 10 %
1 V
100 mA
≤ 10 mA
≤ 10 µA
250
≤ 15 %
-25 ° C to 70 ° C
≤ 10 %
≤ 3 %
LED
yes
yes
yes
IP67
DIN EN 60947-5-2: 2008
2 m
DC 13
PVC grau (grey) LIYY
3x0.14 mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313150430](#)