

[Article Page](#)

Product Description
Name
Order number
Switching distance
Mounting

inductive sensor metal face DC
SJD10-M30EB80-DNÖ-V2
08313301141
10 mm




Switch type



Signal Type
Connection



Connection diagramm

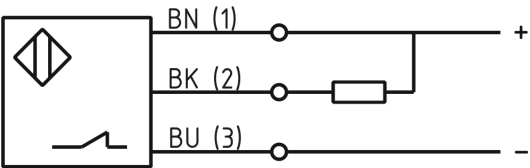

Technical Specification
Operating voltage
Max. ripple
Voltage drop
Max. load current
No load current
Leakage current
Switching frequency
Switching hysteresis
Operating temperature
Temperature drift
Repeat accuracy
Switching state
Digital output
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

10 - 30 V DC
 $\leq 10 \%$
1,5 V
200 mA
 $\leq 10 \text{ mA}$
 $\leq 10 \mu\text{A}$
300
 $\leq 15 \%$
-25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 1 \%$
LED
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Stainless steel V2A
Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08313301141](#)