

Pin Spacing: 5.00mm
 Orientation: Vertical Header
 Clamp Type: –
 Design: Single Mold-Open End


PVxx-5.00
ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	–
	16A	450V	–


INSTALLATION DATA

Screw Size	–	PCB Hole Size	1.5mm
Torque	–	Stripping Lgth.	–


MATERIAL

Body	Polyamide	Screw	–
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	–
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PV02-5.00	10.0	100
3	PV03-5.00	15.0	100
4	PV04-5.00	20.0	50
5	PV05-5.00	25.0	50
6	PV06-5.00	30.0	50
7	PV07-5.00	35.0	50
8	PV08-5.00	40.0	50
9	PV09-5.00	45.0	50
10	PV10-5.00	50.0	50
11	PV11-5.00	55.0	50
12	PV12-5.00	60.0	50
13	PV13-5.00	65.0	20
14	PV14-5.00	70.0	20
15	PV15-5.00	75.0	20
16	PV16-5.00	80.0	20
17	PV17-5.00	85.0	20
18	PV18-5.00	90.0	20
19	PV19-5.00	95.0	20
20	PV20-5.00	100.0	20
21	PV21-5.00	105.0	20
22	PV22-5.00	110.0	20
23	PV23-5.00	115.0	20
24	PV24-5.00	120.0	20

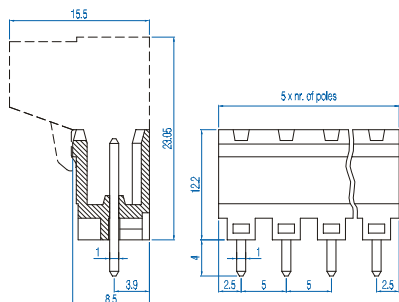

Pin Spacing: 5.00mm
 Orientation: Horizontal Header
 Clamp Type: –
 Design: Single Mold - Open End

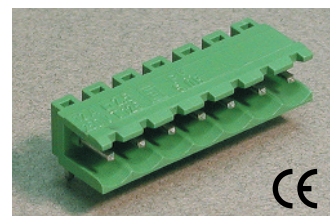
PHxx-5.00
ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	–
	16A	450V	–


INSTALLATION DATA

Screw Size	–	PCB Hole Size	1.5mm
Torque	–	Stripping Lgth.	–

MATERIAL

Body	Polyamide	Screw	–
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	–
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PH02-5.00	10.0	100
3	PH03-5.00	15.0	100
4	PH04-5.00	20.0	50
5	PH05-5.00	25.0	50
6	PH06-5.00	30.0	50
7	PH07-5.00	35.0	50
8	PH08-5.00	40.0	50
9	PH09-5.00	45.0	50
10	PH10-5.00	50.0	50
11	PH11-5.00	55.0	50
12	PH12-5.00	60.0	50
13	PH13-5.00	65.0	20
14	PH14-5.00	70.0	20
15	PH15-5.00	75.0	20
16	PH16-5.00	80.0	20
17	PH17-5.00	85.0	20
18	PH18-5.00	90.0	20
19	PH19-5.00	95.0	20
20	PH20-5.00	100.0	20
21	PH21-5.00	105.0	20
22	PH22-5.00	110.0	20
23	PH23-5.00	115.0	20
24	PH24-5.00	120.0	20

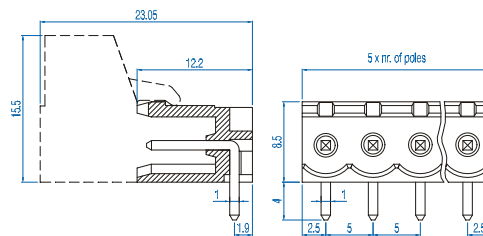

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[PH02-5,00](#) [PH03-5,00](#) [PH04-5,00](#) [PH05-5,00](#) [PH06-5,00](#) [PH07-5,00](#) [PH08-5,00](#) [PH09-5,00](#) [PH10-5,00](#) [PH11-5,00](#) [PH12-5,00](#) [PH13-5,00](#) [PH14-5,00](#) [PH15-5,00](#) [PH16-5,00](#) [PH17-5,00](#) [PH18-5,00](#) [PH19-5,00](#) [PH20-5,00](#) [PH21-5,00](#) [PH22-5,00](#) [PH23-5,00](#) [PH24-5,00](#) [PV02-5,00](#) [PV03-5,00](#) [PV04-5,00](#) [PV05-5,00](#) [PV06-5,00](#) [PV07-5,00](#) [PV08-5,00](#) [PV09-5,00](#) [PV10-5,00](#) [PV11-5,00](#) [PV12-5,00](#) [PV13-5,00](#) [PV14-5,00](#) [PV15-5,00](#) [PV16-5,00](#) [PV17-5,00](#) [PV18-5,00](#) [PV19-5,00](#) [PV20-5,00](#) [PV21-5,00](#) [PV22-5,00](#) [PV23-5,00](#) [PV24-5,00](#)