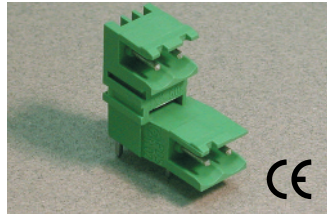


Pin Spacing: 5.08mm
 Orientation: Horizontal - Double
 Level Header
 Clamp Type: —
 Design: Modular - Open End


PDSHxx-5.08
ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	—
	16A	450V	—


**INSTALLATION
DATA**

Screw Size	—	PCB Hole Size	1.5mm
Torque	—	Stripping Lgth.	—


MATERIAL

Body	Polyamide	Screw	—
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	—
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
4	PDSH02-5.08	12.7	100
6	PDSH03-5.08	17.8	100
8	PDSH04-5.08	22.9	50
10	PDSH05-5.08	28.0	50
12	PDSH06-5.08	33.0	50
14	PDSH07-5.08	38.0	50
16	PDSH08-5.08	43.2	50
18	PDSH09-5.08	48.3	50
20	PDSH10-5.08	53.3	50
22	PDSH11-5.08	58.4	20
24	PDSH12-5.08	63.5	20
26	PDSH13-5.08	68.6	20
28	PDSH14-5.08	73.7	20
30	PDSH15-5.08	78.7	20
32	PDSH16-5.08	83.8	20
34	PDSH17-5.08	89.9	20
36	PDSH18-5.08	94.0	20
38	PDSH19-5.08	99.1	20
40	PDSH20-5.08	104.1	10
42	PDSH21-5.08	109.2	10
44	PDSH22-5.08	114.3	10
46	PDSH23-5.08	119.4	10
48	PDSH24-5.08	124.5	10

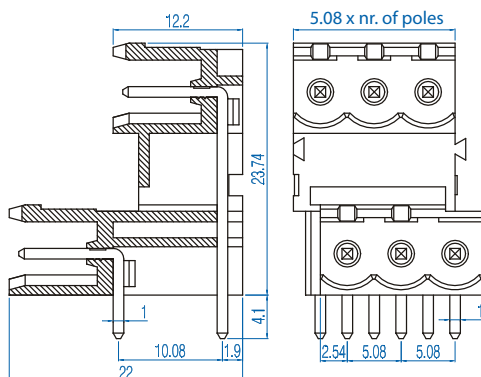

Pin Spacing: 5.08mm
 Orientation: Dual Row
 Vertical Header
 Clamp Type: —
 Design: Single Mold

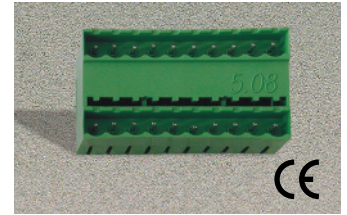
PDVxx-5.08
ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	—
	16A	450V	—


**INSTALLATION
DATA**

Screw Size	—	PCB Hole Size	1.5mm
Torque	—	Stripping Lgth.	—

MATERIAL

Body	Polyamide	Screw	—
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	—
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PDV02-5.08	12.2	100
3	PDV03-5.08	17.2	100
4	PDV04-5.08	22.3	50
5	PDV05-5.08	27.4	50
6	PDV06-5.08	32.5	50
7	PDV07-5.08	37.6	50
8	PDV08-5.08	42.6	50
9	PDV09-5.08	47.7	50
10	PDV10-5.08	52.8	50
11	PDV11-5.08	57.9	50
12	PDV12-5.08	63.0	50

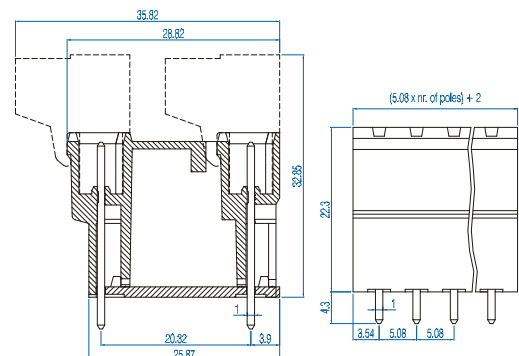

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[PDSH21-5.08](#) [PDSH11-5.08](#) [PDSH08-5.08](#) [PDSH18-5.08](#) [PDSH17-5.08](#) [PDSH07-5.08](#) [PDSH23-5.08](#) [PDSH03-5.08](#) [PDSH13-5.08](#) [PDSH15-5.08](#) [PDSH05-5.08](#) [PDSH02-5.08](#) [PDSH22-5.08](#) [PDSH12-5.08](#) [PDSH16-5.08](#) [PDSH06-5.08](#) [PDSH10-5.08](#) [PDSH20-5.08](#) [PDSH09-5.08](#) [PDSH19-5.08](#) [PDSH24-5.08](#) [PDSH14-5.08](#)