


Pin Spacing: 5.08mm
 Orientation: Horizontal Header with
 Screw Flange
 Clamp Type: –
 Design: Single Mold

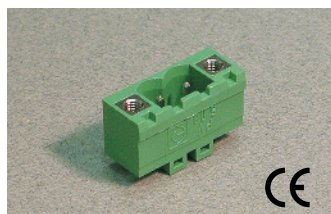

PHxx-5.08-K

ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	–
	16A	450V	–


INSTALLATION DATA

Screw Size	–	PCB Hole Size	1.5mm
Torque	–	Stripping Lgth.	–

MATERIAL

Body	Polyamide	Screw	–
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	Nickeled Brass
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PH02-5.08 - K	20.3	100
3	PH03-5.08 - K	25.4	100
4	PH04-5.08 - K	30.5	50
5	PH05-5.08 - K	35.6	50
6	PH06-5.08 - K	40.6	50
7	PH07-5.08 - K	45.7	50
8	PH08-5.08 - K	50.8	50
9	PH09-5.08 - K	55.9	50
10	PH10-5.08 - K	61.0	50
11	PH11-5.08 - K	66.0	50
12	PH12-5.08 - K	71.1	50
13	PH13-5.08 - K	76.2	20
14	PH14-5.08 - K	81.3	20
15	PH15-5.08 - K	86.4	20
16	PH16-5.08 - K	91.4	20
17	PH17-5.08 - K	96.5	20
18	PH18-5.08 - K	101.6	20
19	PH19-5.08 - K	106.7	20
20	PH20-5.08 - K	111.8	20
21	PH21-5.08 - K	116.6	20
22	PH22-5.08 - K	121.9	20

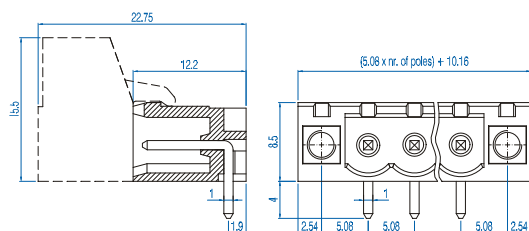

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[PH02-5,08-K](#) [PH03-5,08-K](#) [PH04-5,08-K](#) [PH05-5,08-K](#) [PH07-5,08-K](#) [PH08-5,08-K](#) [PH09-5,08-K](#) [PH10-5,08-K](#)
[PH11-5,08-K](#) [PH12-5,08-K](#) [PH13-5,08-K](#) [PH14-5,08-K](#) [PH15-5,08-K](#) [PH16-5,08-K](#) [PH17-5,08-K](#) [PH18-5,08-K](#)
[PH19-5,08-K](#) [PH21-5,08-K](#) [PH22-5,08-K](#)