


10.00mm Pin Spacing – Pluggable PCB Blocks

Pin Spacing: 10.00mm
Orientation: Horizontal Plug
Clamp Type: Screw Cage
Design: Single Mold

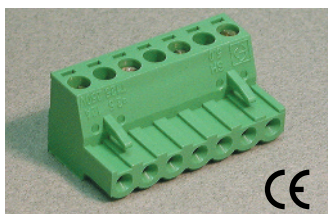

SHxx-10.00

ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	30-14AWG
	16A	750V	2.5mm² Stranded 4.0mm² Solid


INSTALLATION DATA

Screw Size	M3	PCB Hole Size	–
Torque	0.5Nm (4.5 lbf-in.)	Stripping Lgth.	7.5mm


MATERIAL

Body	Polyamide	Screw	Galvanized Steel
Flammability Class	UL94V-0	Terminal	Nickel Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	Nickel Brass
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	SH02-10.00	15.0	100
3	SH03-10.00	25.0	100
4	SH04-10.00	35.0	50
5	SH05-10.00	45.0	50
6	SH06-10.00	55.0	50
7	SH07-10.00	65.0	50
8	SH08-10.00	75.0	50
9	SH09-10.00	85.0	50
10	SH10-10.00	95.0	50
11	SH11-10.00	105.0	20
12	SH12-10.00	115.0	20

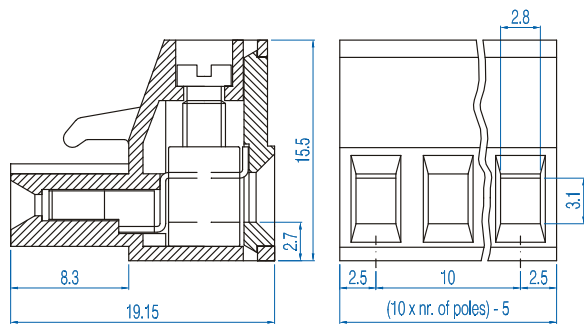

Pin Spacing: 10.00mm
Orientation: Vertical Header
Clamp Type: –
Design: Single Mold - Open End

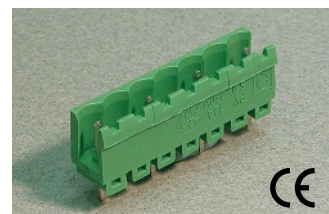

PVxx-10.00

ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	–
	16A	750V	–


INSTALLATION DATA

Screw Size	–	PCB Hole Size	1.5mm
Torque	–	Stripping Lgth.	–

MATERIAL

Body	Polyamide	Screw	–
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	–
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PV02-10.00	15.0	100
3	PV03-10.00	25.0	100
4	PV04-10.00	35.0	50
5	PV05-10.00	45.0	50
6	PV06-10.00	55.0	50
7	PV07-10.00	65.0	50
8	PV08-10.00	75.0	50
9	PV09-10.00	85.0	50
10	PV10-10.00	95.0	50
11	PV11-10.00	105.0	20
12	PV12-10.00	115.0	20

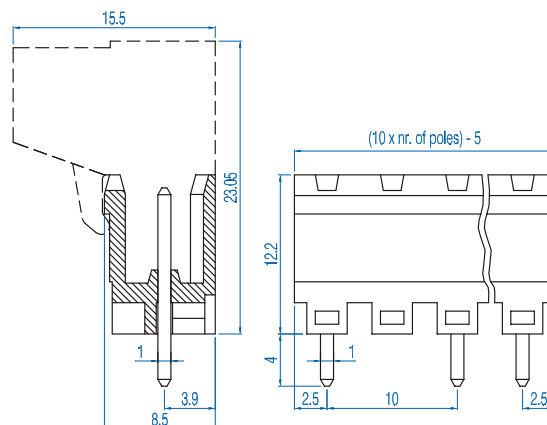

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

<u>PV02-10,00</u>	<u>PV03-10,00</u>	<u>PV04-10,00</u>	<u>PV05-10,00</u>	<u>PV06-10,00</u>	<u>PV07-10,00</u>	<u>PV08-10,00</u>	<u>PV09-10,00</u>	<u>PV10-10,00</u>
<u>PV11-10,00</u>	<u>PV12-10,00</u>	<u>SH02-10,00</u>	<u>SH03-10,00</u>	<u>SH04-10,00</u>	<u>SH05-10,00</u>	<u>SH06-10,00</u>	<u>SH07-10,00</u>	<u>SH08-10,00</u>
<u>SH09-10,00</u>	<u>SH10-10,00</u>	<u>SH11-10,00</u>	<u>SH12-10,00</u>					