


10.00mm Pin Spacing – Pluggable PCB Blocks

Pin Spacing: 10.00mm
Orientation: Horizontal Header
Clamp Type: –
Design: Single Mold - Closed End

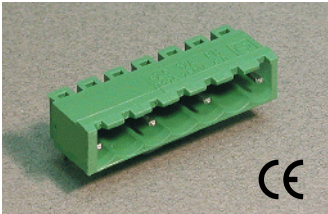

PHPxx-10.00

ELECTRICAL

	Current	Voltage	Wire Range
 US E178356	12A	300V	–
	16A	750V	–


INSTALLATION DATA

Screw Size	–	PCB Hole Size	1.5mm
Torque	–	Stripping Lgth.	–

MATERIAL

Body	Polyamide	Screw	–
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	–
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PHP02-10.00	17.0	100
3	PHP03-10.00	27.0	100
4	PHP04-10.00	37.0	50
7	PHP07-10.00	47.0	50
6	PHP06-10.00	57.0	50
7	PHP07-10.00	67.0	50
8	PHP08-10.00	77.0	50
9	PHP09-10.00	87.0	50
10	PHP10-10.00	97.0	50
11	PHP11-10.00	107.0	20
12	PHP12-10.00	117.0	20

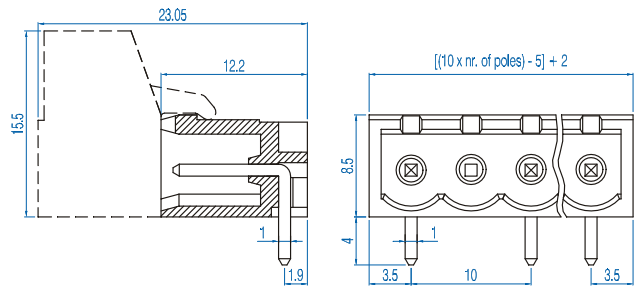

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[PHP02-10,00](#) [PHP03-10,00](#) [PHP04-10,00](#) [PHP05-10,00](#) [PHP06-10,00](#) [PHP07-10,00](#) [PHP08-10,00](#) [PHP09-10,00](#)
[PHP10-10,00](#) [PHP11-10,00](#) [PHP12-10,00](#)