

Fuse Blocks, 5 x 20 and 5 x 25 mm


Altech fuse terminals are also available with light indication - CF4U(L). A specially designed built-in circuit gives light indication in the event of fuse blow out. Thus, fault in a circuit can be easily located. No polarity is required.

Important:

The disconnecting device is not suitable for interrupting load. The supply must be switched off before operating the slide link/lever.

† Fuses are sold separately see pages 100-101.

* Add required voltage to part number as a suffix. i.e. CF4U(L)/6-60 V AC/DC.

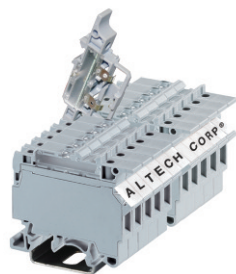

Terminal Width	8 mm
Height x Length	57.6 x 57 mm
Stripping Length	9.5 mm
Insulation Material	Polyamide 6.6
Type of Connection	2 screw clamps
LED Voltage	6-60 V AC/DC 90-240 V AC/DC
Size of Fuse Used Type of Fuse Used	Ø5x20, Ø5x25 mm Glass
Approvals	
Wire Range	22-10 AWG
Voltage Rating	600 V
Current Rating	10 A
Torque	7 lb-in
Other Approvals	

Terminal Block

DIN Rail
for ordering information
refer to pages 90-91

End Stop
for ordering information
refer to page 92

Internal Jumper	2 pole	
	3 pole	
	4 pole	
	10 pole	

Insulated Internal Jumper	2 pole	
	3 pole	
	4 pole	
	10 pole	

Current Bar	2 pole	
	3 pole	
	4 pole	
	10 pole	

Shorting Sleeve & Screw

External Jumper	2 pole	
	3 pole	
	4 pole	
	10 pole	

Marking Tags (on terminal)
(on Lever)

CF4U†

NEW

No End Plate Required.

8 mm
57.6 x 57 mm
9.5 mm
Polyamide 6.6
2 screw clamps
Ø5x20, Ø5x25 mm Glass
22-10 AWG
600 V
10 A
7 lb-in

RoHS
CE

Cat. No.	Std. Pk.
----------	----------

CF4U	100
------	-----

32mm	35mm
------	------

CA702	50
CA802	50

CA711/2	100
CA711/3	50
CA711/4	50
CA711/10	20

MT8	100
MT8	100

CF4U(L)†*

NEW

No Polarity Required.

8 mm
57.6 x 57 mm
9.5 mm
Polyamide 6.6
2 screw clamps
CF4U(L)/6-60V CF4U(L)/90-240V
Ø5x20, Ø5x25 mm Glass
22-10 AWG
600 V
10 A
7 lb-in

RoHS
CE



Cat. No.	Std. Pk.
----------	----------

CF4U(L)*	50
----------	----

32mm	35mm
------	------

CA702	50
CA802	50

CF4U(L) Only

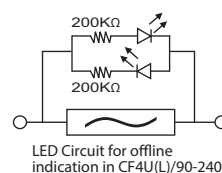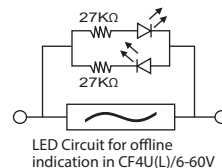

CA711/2	100
CA711/3	50
CA711/4	50
CA711/10	25

MT8	100
MT8	100

COLOR BLOCKS
(other than standard grey)

When ordering please add color suffix to Cat. No.

Example for color Red: **Cat.No./R**

Color	Ordering Suffix
Red	R
Yellow	Y
Blue	BU
Green	G

Consult Altech for availability:

Orange	O
Beige	BG
Dark Brown	DB
Black	BL
White	W

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CF4U/BL](#) [CF4U/R](#)