


Fuse Blocks, 5 x 20 and 5 x 25 mm

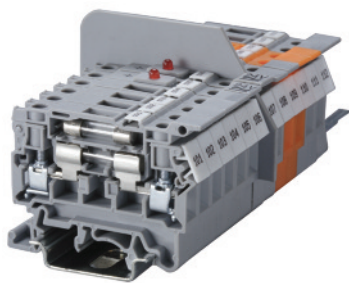

DDFL4ULR is a modified version of the DDFL4U terminal where two equipotential connection points are available on both ends of the terminal.

DDFL4U(E)LR* is similar to the DDFL4ULR, but has a built in circuit that gives light indication in the event of a blown fuse.


Important:

The disconnecting device is not suitable for interrupting load. The supply must be switched off before operating the slide link/lever.

† Fuses are sold separately
Altech, see pages 100-101.


* Add required voltage to part number as suffix, i.e.
DDFL4U(E)LR/24 for 24V AC/DC

DDFL4ULR

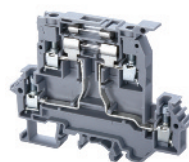

† Fuse not included.

DDFL4U(E)LR*

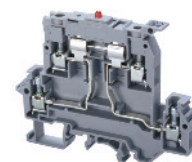

† Fuse not included.

Terminal Width

8 mm

8 mm

Height x Length

66 x 88 mm

66 x 88 mm

Stripping Length

9.5 mm

9.5 mm

Insulation Material

Polyamide 6.6

Polyamide 6.6

Type of Connection

4 screw clamps & 1 tapped hole for cross connection

4 screw clamps & 1 tapped hole for cross connection

LED Voltage

24V AC/DC, 48V AC/DC, 110V AC/DC, 220V AC

Type of Fuse Used

Ø5x20, Ø5x25 mm

Ø5x20, Ø5x25 mm

Approvals



Wire Range

22-10 AWG 0.2-4 mm² 22-10 AWG

22-10 AWG 0.2-4 sq.mm 22-10 AWG

Voltage Rating

600 V 800 V 600 V

600 V 800 V 600 V

Current Rating Top Level

6.3 A 6.3 A 6.3 A

6.3 A 6.3 A 6.3 A

Torque

7 lb-in 0.5 N 7 lb-in

7 lb-in 0.5 Nm 7 lb-in

Other Approvals



Cat. No. Std. Pk.

Cat. No. Std. Pk.

DDFL4ULR 20

DDFL4U(E)LR* 20

EPDDFL4U 20

EPDDFL4U 20



Terminal Block

End Plate



DIN Rail
for ordering information
refer to pages 90-91

End Stop
for ordering information
refer to page 92



Internal Jumper 2 pole 3 pole 4 pole 10 pole



Insulated Internal Jumper 2 pole 3 pole 4 pole 10 pole



Current Bar 2 pole 3 pole 4 pole 10 pole



Shorting Sleeve & Screw



External Jumper 2 pole 3 pole 4 pole 10 pole



Marking Tags (on terminal) (on lever)



CA702 50
CA802 50
CA202 50

CA702 50
CA802 50
CA202 50

CA730/2 100
CA730/3 50
CA730/4 50
CA730/10 10

CA730/2 100
CA730/3 50
CA730/4 50
CA730/10 10

CA740/2 100
CA740/3 50
CA740/4 50
CA740/10 10

CA740/2 100
CA740/3 50
CA740/4 50
CA740/10 10

CA703/7 100
CA704/7 100
CA705/7 100
CA738/10 100

CA703/7 100
CA704/7 100
CA705/7 100
CA738/10 100

CA707/S/Q/8 100

CA707/S/Q/8 100

CA711/2 100
CA711/3 100
CA711/4 50
CA711/10 25

CA711/2 100
CA711/3 100
CA711/4 50
CA711/10 25

MT8 100
MT2 100

MT8 100
MT2 100

COLOR BLOCKS

(other than standard grey)

When ordering please add color suffix to Cat. No.

Example for color Red: Cat.No./R

Color	Ordering Suffix
Red	R
Yellow	Y
Blue	BU
Green	G

Consult Altech for availability:

Orange	O
Beige	BG
Dark Brown	DB
Black	BL
White	W

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[DDFL4ULR](#)