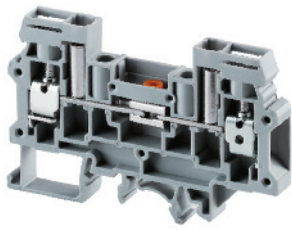


CDS6U


8 mm

50 x 82 mm

10 mm

Polyamide 6.6

2 screw clamps



22-8 AWG

0.2-6 sq.mm

22-8 AWG

600 V

800 V

600 V

45 A

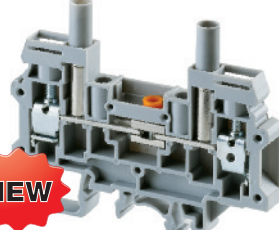
41 A

45 A

14 lb-in

0.8 Nm

14 lb-in


CDS6U/TS

NEW

8 mm

50 x 82 mm

10 mm

Polyamide 6.6

2 screw clamps



22-8 AWG

0.2-6 sq.mm

22-8 AWG

600 V

630 V

600 V

45 A

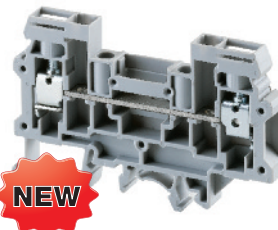
41 A

45 A

14 lb-in

0.8 Nm

14 lb-in


CDS6U/FT

NEW

6 mm

50 x 82 mm

10 mm

Polyamide 6.6

2 screw clamps



22-8 AWG

0.2-6 sq.mm

22-8 AWG

600 V

1000 V

600 V

45 A

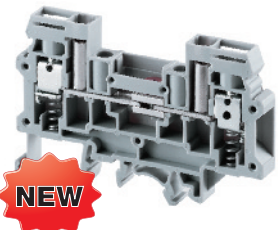
41 A

45 A

14 lb-in

0.8 Nm

14 lb-in


CDS6U/SC

NEW

6 mm

50 x 82 mm

10 mm

Polyamide 6.6

2 screw clamps



22-8 AWG

0.2-6 sq.mm

22-8 AWG

600 V

800 V

600 V

45 A

41 A

45 A

14 lb-in

0.8 Nm

14 lb-in



Cat. No.	Std. Pk.
----------	----------

CDS6U 50

EPCDS6U 50


CA702 50
CA802 50

CA723/2 100
CA723/3 50
CA723/4 50
CA723/5 50
CA723/10 10

SLS2 50
SLS4 25

TPSLS 100
TPSLSR 100
TPSLSY 100
TPSLSBU 100
TPSLSBK 100

SWCDS 50

LCCDS 50

MT8 100

Cat. No.	Std. Pk.
----------	----------

CDS6U/TS 50

EPCDS6U 50


CA702 50
CA802 5

CA723/2 100
CA723/3 50
CA723/4 50
CA723/5 50
CA723/10 10

SLS2 50
SLS4 25

TPSLSR 100
TPSLSY 100
TPSLSBU 100
TPSLSBK 100

SWCDS 50

LCCDS 50

MT8 100

Cat. No.	Std. Pk.
----------	----------

CDS6U/FT 50

EPCDS6U 50


CA702 50
CA802 5

CA723/2 100
CA723/3 50
CA723/4 50
CA723/5 50
CA723/10 10

SLS2 50
SLS4 25

TPSLS 100
TPSLSR 100
TPSLSY 100
TPSLSBU 100
TPSLSBK 100

SWCDS 50

LCCDS 50

MT8 100

Cat. No.	Std. Pk.
----------	----------

CDS6U/SC 50

EPCDS6U 50


CA702 50
CA802 5

CA723/2 100
CA723/3 50
CA723/4 50
CA723/5 50
CA723/10 10

SLS2 50
SLS4 25

TPSLS 100
TPSLSR 100
TPSLSY 100
TPSLSBU 100
TPSLSBK 100

SWCDS 50

LCCDS 50

MT8 100

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CDS6U](#) [CDS6U/FT](#) [CDS6U/TS](#) [CDS6U/SC](#)