



Feed-Through & Multi-Connection Spring Clamp

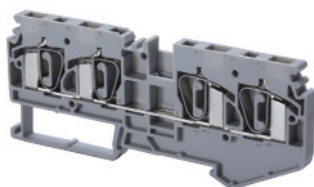

CSC4T2-2



CSC6T1-2

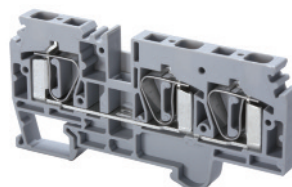

Terminal Width

6 mm

8 mm

Height x Length

42 x 105 mm

45 x 94 mm

Stripping Length

15 mm

15 mm

Insulation Material

Polyamide 6.6

Polyamide 6.6

Type of Connection

4 spring clamps & 2 slots for interconnection

3 spring clamps & 2 slots for interconnection

Approvals



Wire Range

22-12 AWG

0.2-4 sq.mm

22-12 AWG

22-8 AWG

0.2-6 sq.mm

22-8 AWG

Voltage Rating

600 V

800 V

600 V

600 V

800 V

600 V

Current Rating

25 A

32 A

 
 
25 A

50 A

41 A

50 A

Other Approvals



Terminal Block

End Plate



DIN Rail
for ordering information
refer to pages 90-91

End Stop
for ordering information
refer to page 92



Jumpers
Adjacent
Alternate



Push in type
wire jumper



Marking Tags



Cat. No. Std. Pk.

CSC4T2-2

50

EPCSC4T2-2

50



CA103
CA702
CA802

50
50
50

CA801/2
CA801/2-3

100
100

CA901/2

100

MT6

100

Cat. No. Std. Pk.

CSC6T1-2

50

EPCSC6T1-2

50



CA103
CA702
CA802

50
50
50

CA801/3
CA801/3-3

100
100

CA901/3

100

MT8

100

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CSC4T2-2](#)