


| COMPONENTS | IMPEDANCE |
|------------|-----------|
| BNC MALE   | 50 OHM    |
| BNC FEMALE | 50 OHM    |
| RG213/U    | 50 OHM    |
|            |           |

| Standard Lengths |                         |
|------------------|-------------------------|
| -12              | 12"                     |
| -24              | 24"                     |
| -36              | 36"                     |
| -48              | 48"                     |
| -60              | 60"                     |
| -xxx             | Custom Length in inches |
|                  |                         |

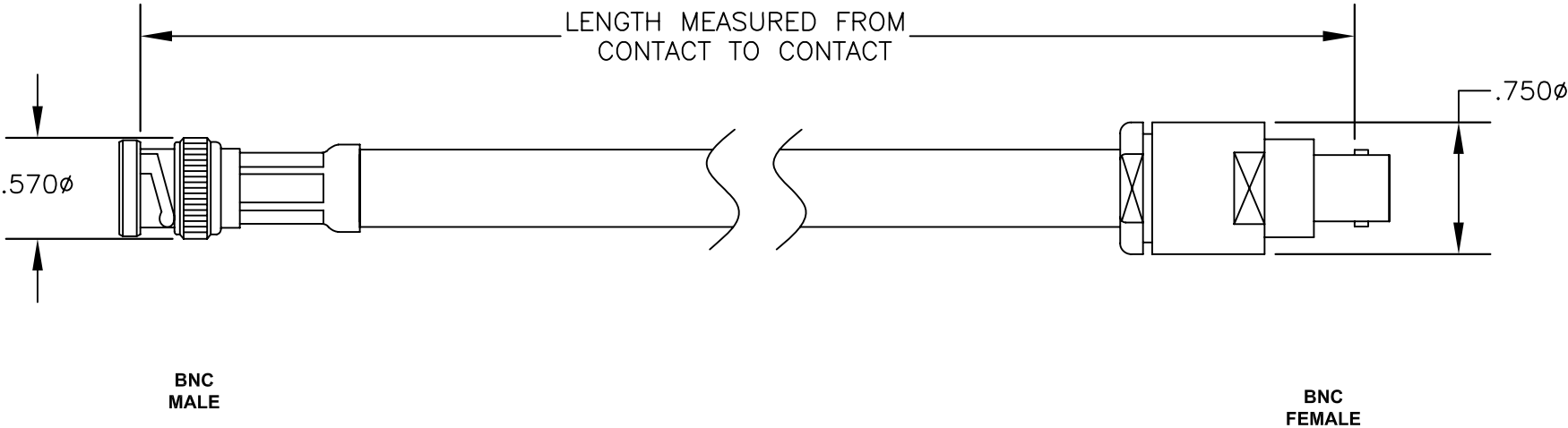



**PASTERNAK ENTERPRISES®**  
ESTABLISHED 1972

**PASTERNAK ENTERPRISES, INC.**  
P.O BOX 16759, IRVINE, CA 92623  
PHONE (949) 261-1920 FAX (949) 261-7451

WEB ADDRESS: [www.pasternack.com](http://www.pasternack.com)  
E-MAIL ADDRESS: [sales@pasternack.com](mailto:sales@pasternack.com)

**COAXIAL & FIBER OPTICS**

|                               |                |                                                      |           |
|-------------------------------|----------------|------------------------------------------------------|-----------|
| DWG TITLE<br><b>PE3949-XX</b> |                | DES. CABLE ASSEMBLY, RG213/U, BNC MALE TO BNC FEMALE |           |
| SIZE A                        | FSCM NO. 53919 | CAD FILE 022107                                      | SCALE N/A |
|                               |                |                                                      | 127       |

- NOTES:
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
  2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
  3. DIMENSIONS ARE IN INCHES.
  4. LENGTH TOLERANCE IS ± 1.5% OR ±3/8", WHICHEVER IS GREATER.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pasternack:](#)

[PE3949-60](#)