


THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

REVISIONS			
REV.	DESCRIPTION	DATE	APPROVED
A	INITIAL RELEASE	01/11/2022	PHOSPODAR

AARC DUST CAP

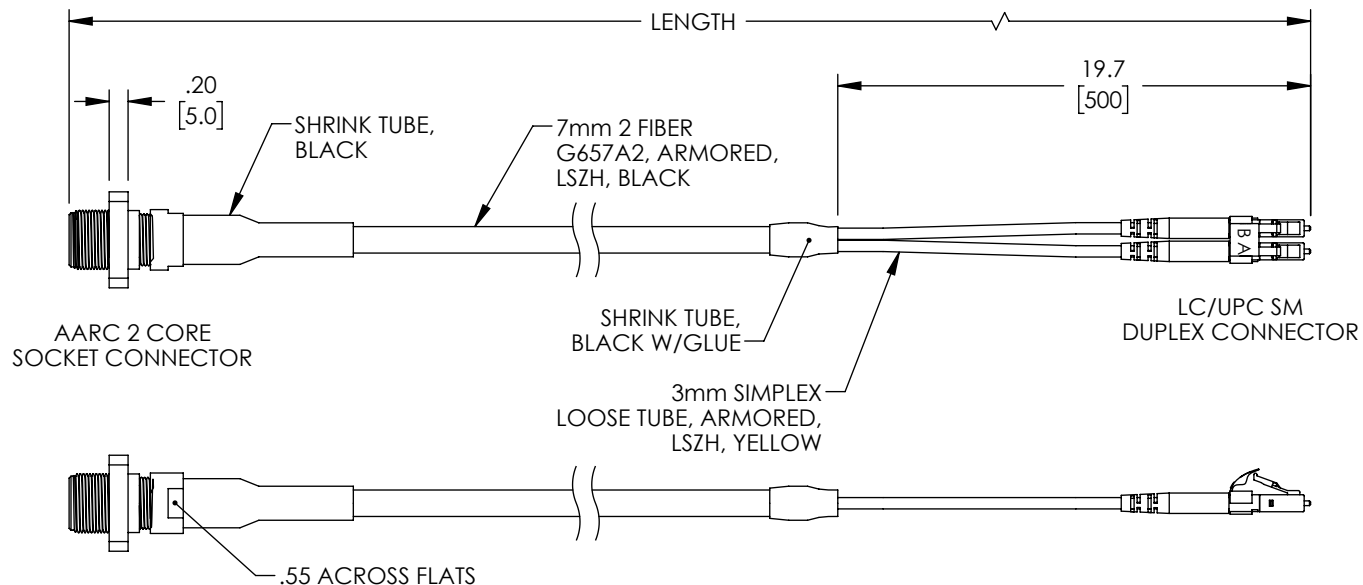

ASSY CONNECTIVITY	
AARC 2 CORE SKT	LC/UPC
PIN1	B
PIN2	A

 
ITEM NO.	LENGTH	
	METER	FEET
FOC02A3027101M	1.0	3.28
FOC02A3027102M	2.0	6.56
FOC02A3027105M	5.0	16.40
FOC02A3027110M	10.0	32.81
FOC02A3027115M	15.0	49.21

NOTES:

1. LC CONNECTOR POLISH TYPE: UPC.
2. AARC CONNECTOR COMES WITH A DUST CAP INSTALLED.
3. LC CONNECTORS COM WITH DUST PLUG INSTALLED (NOT SHOWN)
4. CABLE ASSEMBLY SHALL BE INDIVIDUALLY PACKAGED IN ACCORDANCE WITH L-COM SPECIFICATION PS-0031.

REGULATORY COMPLIANCE:

EU RoHS DIRECTIVE (MOST RECENT RELEASED VERSION)

UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE IN INCHES [mm]		APPROVALS		DATE		 an INFINITI™ brand		50 High Street, West Mill, North Andover, MA 01845 USA Phone: 1.800.341.5266 1.978.682.6936	
OVERALL CABLE LENGTH TOLERANCE: ≤12 [305] = +1 [25] / -0 >12 [305] ≤60 [1524] = +2 [51] / -0 >60 [1524] ≤120 [3048] = +4 [102] / -0 >120 [3048] ≤300 [7620] = +6 [152] / -0 >300 [7620] = +5% / -0		DRAWN BY DZINN		01/18/2022					
ALL OTHER DIMENSIONAL TOLERANCES: .X = ± .2 [5] FRACTIONS .XX = ± .02 [.5] ± 1/32 .XXX = ± .005 [.13] ANGLES ± 1°		CHECKED BY DFRISIELLO		01/18/2022					
THIRD-ANGLE PROJECTION 		APPROVED BY PHOSPODAR		01/18/2022		CATEGORY FIBER OPTIC		PRODUCT DESCRIPTION Fiber Optic Outdoor patch cable, Duplex SMF(G.657.A2), 2 core AARC(Socket) to dual clipped LC/UPC with Armored 7.0mm LSZH jacket	
		CONFIGURATION DETAILS OF UNDIMENSIONED FEATURES MAY VARY		COLOR VARIATIONS MAY OCCUR		SIZE A	CAGE CODE 43321	ITEM NO. FOC02A30271	REV. A
						SCALE: NONE	CAD FILE: FOC02A30271.SLDDRW		SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[L-Com:](#)

[FOC02A3027110M](#) [FOC02A3027101M](#) [FOC02A3027105M](#) [FOC02A3027102M](#) [FOC02A3027115M](#)