


THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

REVISIONS			
REV	DESCRIPTION	DATE	APPROVED
A	INITIAL RELEASE	05/11/2023	GUTTADAURO

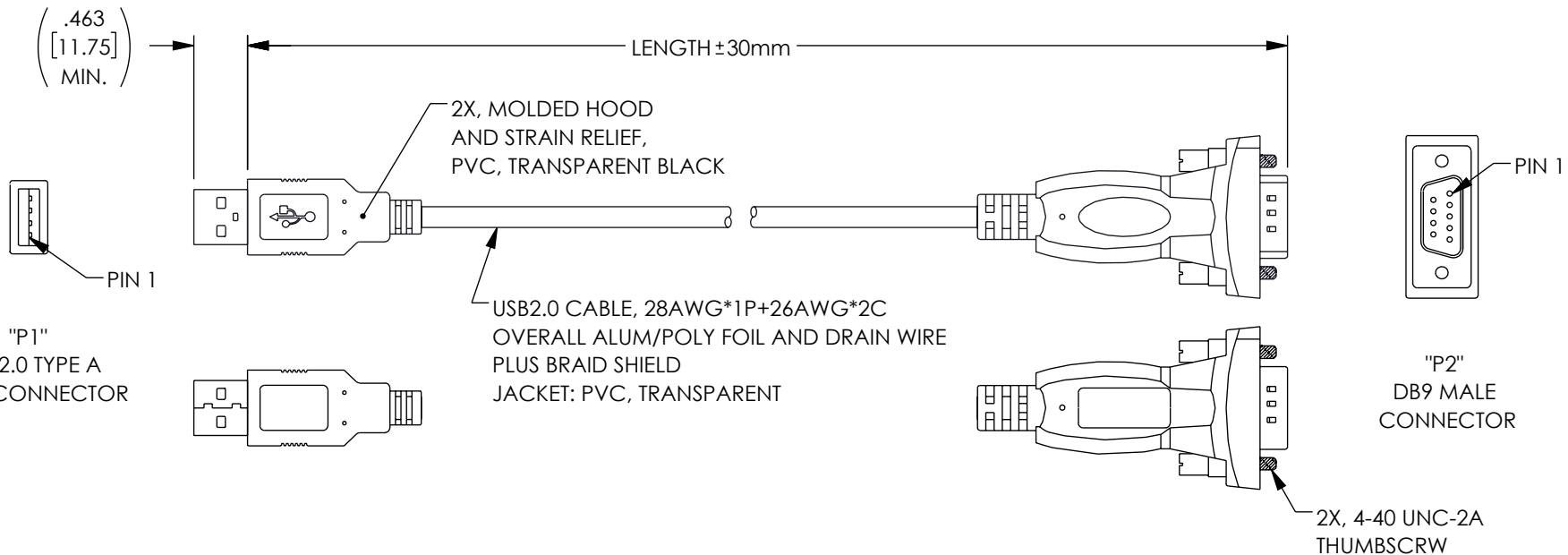


 
PART NUMBER	LENGTH (MILLIMETER)
USB2.0-RS232-1M	1000
USB2.0-RS232-1.5M	1500
USB2.0-RS232-2M	2000

FEATURES:

USB 2.0 VERSION
OVER 1Mbps DATA TRANSFER RATE.
COMPATIBLE WITH WINDOWS, MAC, LINUX, ANDROID SYSTEM

PACKAGING:

CABLE ASSEMBLY SHALL BE INDIVIDUALLY PACKAGED IN ACCORDANCE WITH L-COM SPECIFICATION PS-0031.

UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE IN INCHES [mm]		APPROVALS		DATE		<div> an INFINITE brand</div> <div>50 High Street, West Mill, North Andover, MA 01845 USA. Phone: 1.800.341.5266 1.978.682.6936</div>	
OVERALL CABLE LENGTH TOLERANCE: ≤12 [305] = +1 [25] / -0 >12 [305] ≤60 [1524] = +2 [51] / -0 >60 [1524] ≤120 [3048] = +4 [102] / -0 >120 [3048] ≤300 [7620] = +6 [152] / -0 >300 [7620] = +5% / -0		DRAWN BY SLI		04/18/2023			
ALL OTHER DIMENSIONAL TOLERANCES: .X = ± .2 [5] FRACTIONS .XX = ± .02 [.5] ± 1/32 .XXX = ± .005 [.13] ANGLES ± 1°		CHECKED BY GUITADAURO		04/18/2023			
		APPROVED BY GUITADAURO		04/18/2023			
		CATEGORY		USB			
		PRODUCT DESCRIPTION		USB TO RS232 CONVERTER CABLE			
		CONFIGURATION DETAILS OF UNDIMENSIONED FEATURES MAY VARY					
THIRD-ANGLE PROJECTION 		COLOR VARIATIONS MAY OCCUR		SIZE A	CAGE CODE 43321	DWG. NO. USB2.0-RS232	REV. A
				SCALE: NONE		CAD FILE: USB2.0-RS232.SLDDRW	
						SHEET 1 OF 1	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[infinite Electronics:](#)

[USB2.0-RS232-2M](#) [USB2.0-RS232-1.5M](#) [USB2.0-RS232-1M](#)