

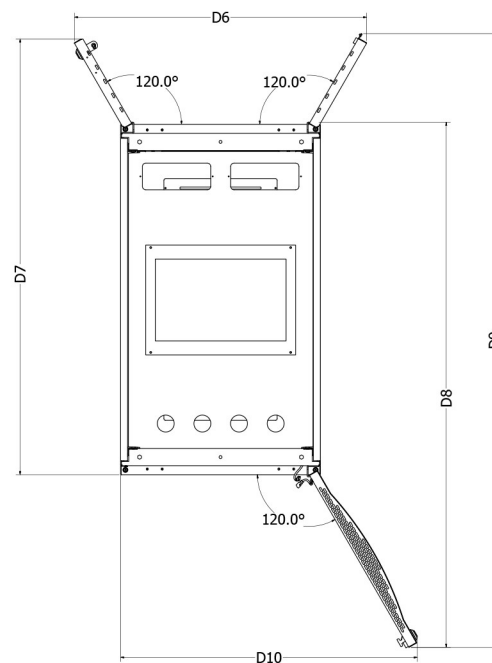
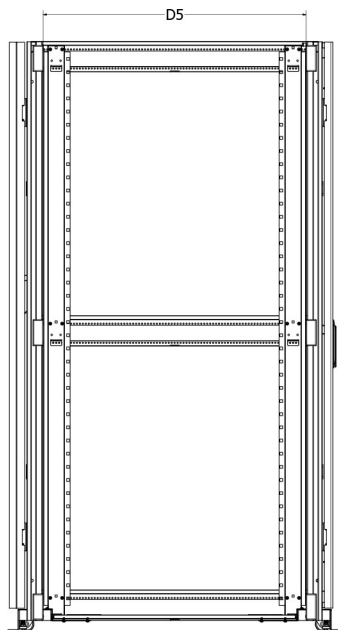
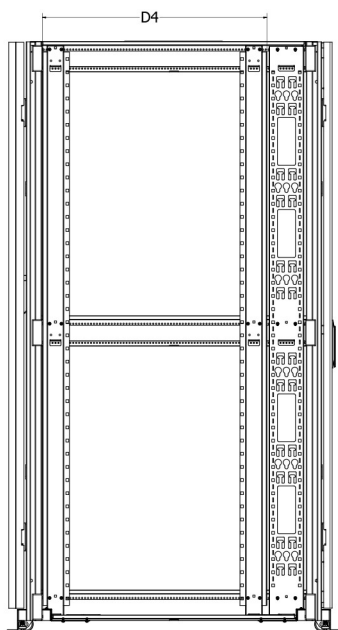
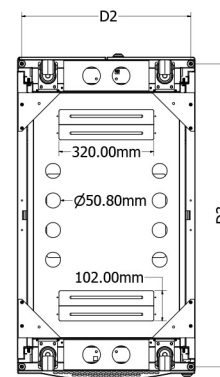
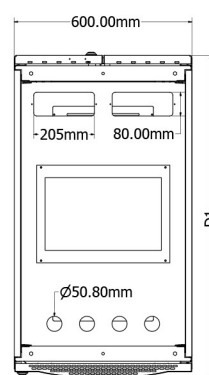


42U Cabinets

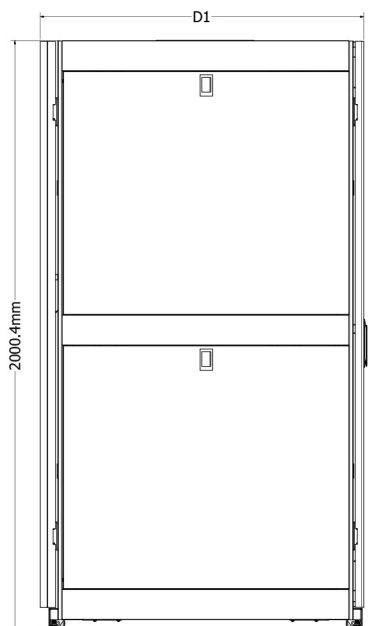

Model / SKU Number	LC42USRC800PDCM	LC42USRC800GDCM	LC42USRC800PDRFC	LC42USRC800GDRFC	LC42USRC800PDCM-W	LC42USRC800GDCM-W	LC42USRC800PDRFC-W	LC42USRC800GDRFC-W	LC42USRC1000PDRFC	LC42USRC1000PDRFCM	LC42USRC1000GDRFC	LC42USRC1000GDRFCM	LC42USRC1000PDRFC-W	LC42USRC1000PDRFCM-W	LC42USRC1000GDRFC-W	LC42USRC1000GDRFCM-W	LC42USRC1200PDRFCM	LC42USRC1200PDRFC	LC42USRC1200GDRFCM	LC42USRC1200GDRFC	LC42USRC1200PDRFCM-W	LC42USRC1200PDRFC-W	LC42USRC1200GDRFCM-W	LC42USRC1200GDRFC-W
Physical																								
Cabinet Size (HxWxD)	42U x 600 mm x 800 mm								42U x 600 mm x 1,000 mm								42U x 600 mm x 1,200 mm							
Features																								
Front Door Type: Perforated	✓		✓		✓		✓		✓	✓			✓	✓			✓	✓			✓	✓		
Front Door Type: Glass		✓		✓		✓		✓			✓				✓	✓			✓			✓		✓
Top Design: Fan			✓	✓			✓	✓			✓				✓	✓			✓			✓		✓
Top Design: Cable Management	✓	✓			✓	✓				✓		✓				✓	✓			✓		✓		✓
DIMENSIONS & SPECIFICATIONS																								
Static Weight Capacity (lbs / kg)	3000 / 1350								3000 / 1350								3000 / 1350							
Weight Capacity on Casters (lbs / kg)	2400 / 1088								2400 / 1088								2400 / 1088							
External Height (mm)	2000.4								2000.4								2000.4							
External Width (mm)	600								600								600							
D1 External Depth (mm)	893								1093								1293							
D2 Distance Between Levelers (mm)	571								571								571							
D3 Distance Between Levelers (mm)	823.2								1023.2								1223.2							
D4 (mm)	555								755								955							
D5 (mm)	680								880								1080							
D6 (mm)	878								878								876							
D7 (mm)	1110								1310								1510							
D8 (mm)	1378								1578								1778							
D9 9mm)	1644								1844								2044							
D10 (mm)	890								890								890							

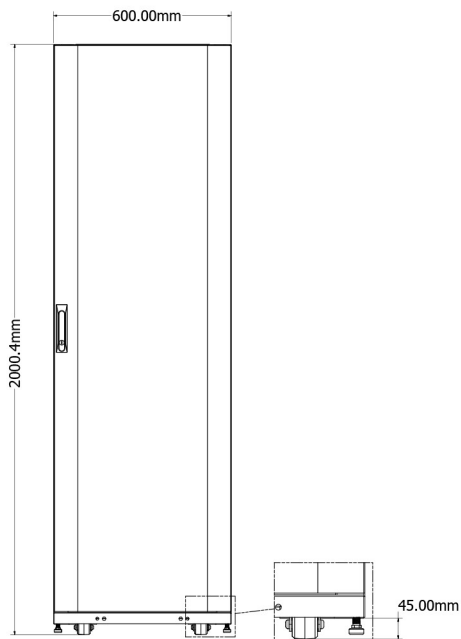

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[L-Com:](#)

[MPM12OM3-09LCR-1](#)