


M28840/10 Wall Mount Receptacle Connector



MIL-DTL
28840

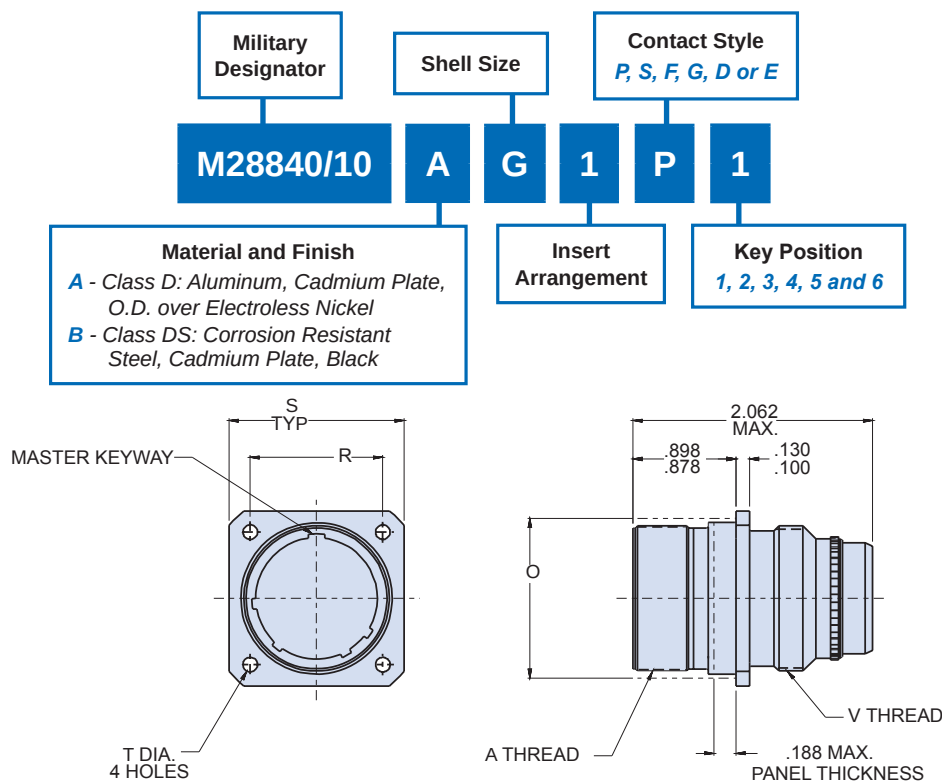

B

Military Shell Size	Shell Size	A Thread Class 2A	V Thread Class 2A	Ø Ref. Mtg. Hole	R True Position ϕ to ϕ	S	T Diameter
A	11	.750-.1P-.2L-D.S.	.750-20 UNEF	.812 (20.62)	.750 (19.05)	1.043 (26.49) 1.003 (25.48)	.130 (3.30) .115 (2.92)
B	13	.875-.1P-.2L-D.S.	.875-20 UNEF	.937 (23.80)	.843 (21.41)	1.158 (29.41) 1.118 (28.40)	
C	15	1.062-.1P-.2L-D.S.	1.000-20 UNEF	1.124 (28.55)	.968 (24.59)	1.278 (32.46) 1.238 (31.45)	
D	17	1.125-.1P-.2L-D.S.	1.125-18 UNEF	1.187 (30.15)	1.015 (25.78)	1.403 (35.64) 1.363 (34.62)	
E	19	1.312-.1P-.2L-D.S.	1.250-18 UNEF	1.374 (34.90)	1.140 (28.96)	1.528 (38.81) 1.488 (37.80)	
F	23	1.500-.1P-.2L-D.S.	1.437-18 UNEF	1.562 (39.67)	1.281 (32.54)	1.738 (44.15) 1.698 (43.13)	
G	25	1.625-.1P-.2L-D.S.	1.562-18 UNEF	1.687 (42.85)	1.392 (35.36)	1.838 (46.69) 1.798 (45.67)	.157 (3.99) .142 (3.61)
H	29	1.812-.1P-.2L-D.S.	1.875-16 UN	1.874 (47.60)	1.568 (39.83)	2.158 (54.81) 2.118 (53.80)	
J	33	2.000-.1P-.2L-D.S.	2.062-16 UNS	2.062 (52.37)	1.734 (44.04)	2.348 (59.64) 2.308 (58.62)	.183 (4.65) .168 (4.27)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

M28840/10AG1F1	M28840/10BC1S1	M28840/10AA1G1	M28840/10AA1P1	M28840/10AA1P2	M28840/10AA1P3
M28840/10AA1P4	M28840/10AA1P5	M28840/10AA1P6	M28840/10AA1S1	M28840/10AB1F1	M28840/10AB1F2
M28840/10AB1G1	M28840/10AB1G2	M28840/10AB1G3	M28840/10AB1P2	M28840/10AB1P3	M28840/10AB1P4
M28840/10AB1P5	M28840/10AB1P6	M28840/10AB1S1	M28840/10AB1S2	M28840/10AB1S3	M28840/10AC1P2
M28840/10AC1P3	M28840/10AC1P4	M28840/10AC1P5	M28840/10AC1S1	M28840/10AC1S2	M28840/10AC1S3
M28840/10AC1S4	M28840/10AC1S6	M28840/10AD1P1	M28840/10AD1S1	M28840/10AD1S2	M28840/10AD1S3
M28840/10AE1P1	M28840/10AE1P2	M28840/10AE1P3	M28840/10AE1S1	M28840/10AE1S2	M28840/10AE1S3
M28840/10AF1P1	M28840/10AF1P2	M28840/10AF1P3	M28840/10AF1S1	M28840/10AF1S2	M28840/10AF1S3
M28840/10AF1S4	M28840/10AF1S5	M28840/10AF1S6	M28840/10AG1D5	M28840/10AG1P1	M28840/10AG1P2
M28840/10AG1P3	M28840/10AG1P4	M28840/10AG1P6	M28840/10AG1S1	M28840/10AG1S3	M28840/10AH1P1
M28840/10AH1S1	M28840/10AH1S2	M28840/10AJ1P1	M28840/10AJ1P4	M28840/10AJ1S1	M28840/10BB1F1
M28840/10BC1P1	M28840/10BC1S3	M28840/10BF1S1	M28840/10AB1P1	M28840/10AC1P1	M28840/10AA1S2
M28840/10AA1S4	M28840/10AJ1F1	M28840/10AG1A1	M28840/10AG1G1	M28840/10AJ1G1	M28840/10AJ1G3
M28840/10AJ1G5	M28840/10AD1P2	M28840/10AD1S4	M28840/10AE1P5	M28840/10BC1S5	M28840/10AF1G2
M28840/10AB1S4	M28840/10BA1S1	M28840/10AF1E4	M28840/10AF1E3	M28840/10AC1S5	M28840/10AG1S5
M28840/10AD1D1	M28840/10AD1E5	M28840/10AD1D2	M28840/10AD1D4	M28840/10AD1E4	M28840/10AD1D5
M28840/10AD1S5	M28840/10AE1P6	M28840/10AD1P4	M28840/10AD1E2		