




440-073 EMI/RFI Banding Adapter Rotatable Coupling - Standard Profile

CONNECTOR DESIGNATORS A-F-H-L-S ROTATABLE COUPLING


Product Series — 440
 Connector Designator — F
 Angle and Profile — S
 H = 45°
 J = 90°
 S = Straight
 Basic Part No. — 073
 Finish (Table II) — NF
 Shell Size (Table I) — 16
 Cable Entry (Table IV) — 12-8
 Polysulfide (Omit for none) — K
 B = Band
 K = Precoiled Band
 (Omit for none)
 Length: S only
 (1/2 inch increments,
 e.g. 8 = 4.000 inches)
 P

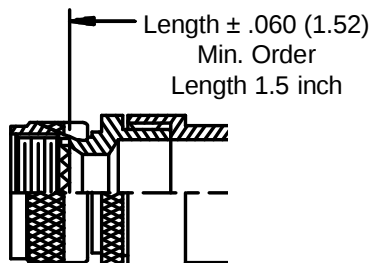

**STYLE 2
(STRAIGHT
See Note 1)**

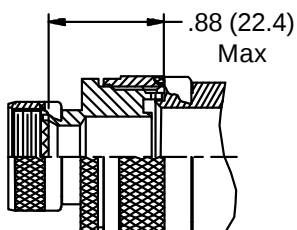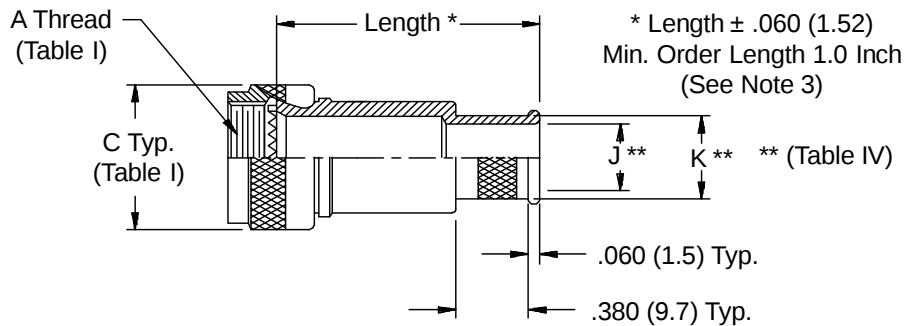


**STYLE 2
(45° & 90°
See Note 1)**


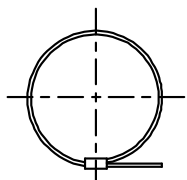


Band Option
(K Option Shown -
See Note 4)

Termination Area
Nickel Plated.
Knurl or Ridges
Mfr's Option

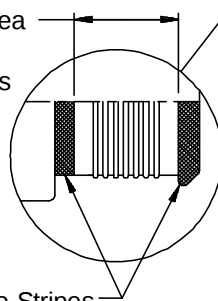

Polysulfide Stripes
P Option

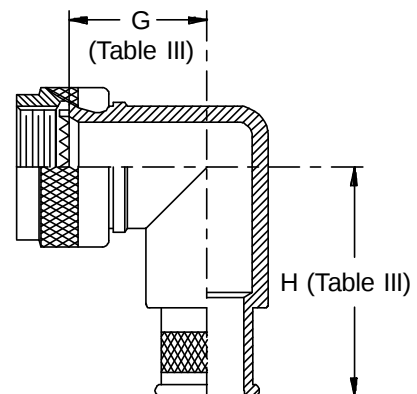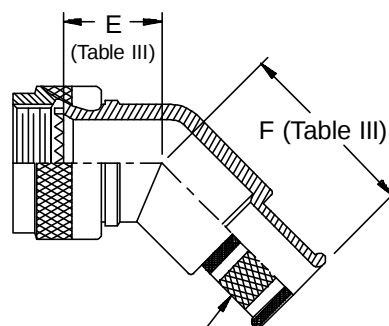

See inside back cover fold-out or pages 13 and 14 for Tables I and II.

TABLE III: ELBOW DIMENSIONS

Shell Size Conn. Desig.		E		F		G		H	
A-F-L-S	H	Max		Max		Max		Max	
08	09	.639	(16.2)	.890	(22.6)	.750	(19.1)	1.000	(25.4)
10	11	.664	(16.9)	.920	(23.4)	.810	(20.6)	1.060	(26.9)
12	13	.688	(17.5)	.940	(23.9)	.870	(22.1)	1.120	(28.4)
14	15	.705	(17.9)	.970	(24.6)	.920	(23.4)	1.190	(30.2)
16	17	.732	(18.6)	.990	(25.1)	.980	(24.9)	1.250	(31.8)
18	19	.748	(19.0)	1.000	(25.4)	1.020	(25.9)	1.270	(32.3)
20	21	.773	(19.6)	1.020	(25.9)	1.080	(27.4)	1.330	(33.8)
22	23	.800	(20.3)	1.060	(26.9)	1.140	(29.0)	1.410	(35.8)
24	25	.823	(20.9)	1.090	(27.7)	1.200	(30.5)	1.480	(37.6)

TABLE IV: CABLE ENTRY

Dash No.	J Dia		K Dia	
02	.125	(3.2)	.250	(6.4)
03	.188	(4.8)	.312	(7.9)
04	.250	(6.4)	.375	(9.5)
05	.312	(7.9)	.438	(11.1)
06	.375	(9.5)	.500	(12.7)
07	.438	(11.1)	.562	(14.3)
08	.500	(12.7)	.625	(15.9)
09	.562	(14.3)	.688	(17.5)
10	.625	(15.9)	.750	(19.1)
11	.688	(17.5)	.812	(20.6)
12	.750	(19.1)	.875	(22.2)
13	.812	(20.6)	.938	(23.8)
14	.875	(22.2)	1.000	(25.4)
15	.938	(23.8)	1.062	(27.0)
16	1.000	(25.4)	1.125	(28.6)
17	1.062	(27.0)	1.188	(30.2)
18	1.125	(28.6)	1.250	(31.8)
20	1.250	(31.8)	1.375	(34.9)
22	1.375	(34.9)	1.500	(38.1)
24	1.500	(38.1)	1.625	(41.3)

1. When maximum cable entry (page 21) is exceeded, Style 2 will be supplied. Dimensions E, F, G and H will not apply. Please consult factory.
2. Metric dimensions (mm) are indicated in parentheses.
3. Consult factory for shorter lengths on straight backshells.
4. Backshells supplied with 600-052-* band, see Glenair Series 600 Tool Catalog for installation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[440HJ073M1105-B](#) [440HS073M0904-2B](#) [440HS073M1103-2B](#) [440HS073M1105-2B](#) [440HS073M1303-3B](#)
[440HS073M1304-3B](#) [440HS073M1508-3B](#) [440HS073M1706-3B](#) [440HS073M1708-3B](#) [440HS073M1905-3B](#)
[440HS073NF1509-2K](#) [440HS073NF1711-2K](#) [440HJ073Z10905-63](#) [440HS073N2302-5](#) [440HS073NF1904-2](#)
[440HS073NF1904-3](#) [440HS073Z11106-2](#) [440HS073Z11711-2](#) [440HS073Z12518-2](#) [440HS073N1305-3](#)
[440HS073N1705-3](#) [440HS073N1905-3](#) [440FJ073NF2214](#)