


# 469-001 Shield Support Ring for Use with G-Spring Backshells



460

For use with  
Series 460 and  
463 G-Spring  
Backshells

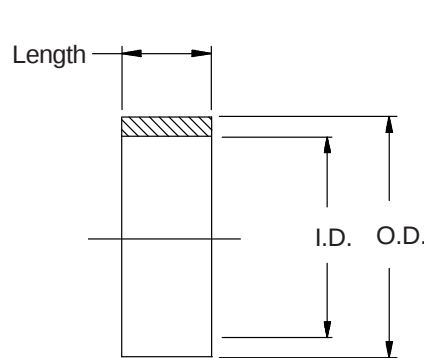

469-001-22  
Basic Part No. \_\_\_\_\_  
Dash No. \_\_\_\_\_

| Dash No. | I.D. ±.010 (.3) | O.D. ±.010 (.3) | Length (Note 2) |
|----------|-----------------|-----------------|-----------------|
| 01       | .187 (4.7)      | .227 (5.8)      | .50 (12.7)      |
| 02       | .218 (5.5)      | .258 (6.6)      | .50 (12.7)      |
| 03       | .250 (6.4)      | .290 (7.4)      | .50 (12.7)      |
| 04       | .281 (7.1)      | .321 (8.2)      | .50 (12.7)      |
| 05       | .312 (7.9)      | .352 (8.9)      | .50 (12.7)      |
| 06       | .343 (8.7)      | .383 (9.7)      | .50 (12.7)      |
| 07       | .375 (9.5)      | .415 (10.5)     | .50 (12.7)      |
| 08       | .406 (10.3)     | .446 (11.3)     | .50 (12.7)      |
| 09       | .438 (11.1)     | .478 (12.1)     | .50 (12.7)      |
| 10       | .468 (11.9)     | .508 (12.9)     | .50 (12.7)      |
| 11       | .500 (12.7)     | .540 (13.7)     | .50 (12.7)      |
| 12       | .531 (13.5)     | .571 (14.5)     | .50 (12.7)      |
| 13       | .562 (14.3)     | .602 (15.3)     | .50 (12.7)      |
| 14       | .593 (15.1)     | .633 (16.1)     | .50 (12.7)      |
| 15       | .625 (15.9)     | .665 (16.9)     | .50 (12.7)      |
| 16       | .656 (16.7)     | .696 (17.7)     | .50 (12.7)      |
| 17       | .687 (17.4)     | .727 (18.5)     | .50 (12.7)      |
| 18       | .718 (18.2)     | .758 (19.3)     | .50 (12.7)      |
| 19       | .750 (19.1)     | .790 (20.1)     | .75 (19.1)      |
| 20       | .781 (19.8)     | .821 (20.9)     | .75 (19.1)      |
| 21       | .812 (20.6)     | .852 (21.6)     | .75 (19.1)      |
| 22       | .843 (21.4)     | .883 (22.4)     | .75 (19.1)      |
| 23       | .875 (22.2)     | .915 (23.2)     | .75 (19.1)      |
| 24       | .906 (23.0)     | .946 (24.0)     | .75 (19.1)      |
| 25       | .937 (23.8)     | .977 (24.8)     | .75 (19.1)      |
| 26       | .968 (24.6)     | 1.008 (25.6)    | .75 (19.1)      |
| 27       | 1.000 (25.4)    | 1.040 (26.4)    | .75 (19.1)      |

| Dash No. | I.D. ±.010 (.3) | O.D. ±.010 (.3) | Length (Note 2) |
|----------|-----------------|-----------------|-----------------|
| 28       | 1.031 (26.2)    | 1.071 (27.2)    | .75 (19.1)      |
| 29       | 1.062 (27.0)    | 1.102 (28.0)    | .75 (19.1)      |
| 30       | 1.093 (27.8)    | 1.133 (28.8)    | .75 (19.1)      |
| 31       | 1.125 (28.6)    | 1.165 (29.6)    | .75 (19.1)      |
| 32       | 1.156 (29.4)    | 1.196 (30.4)    | .75 (19.1)      |
| 33       | 1.187 (30.1)    | 1.227 (31.2)    | .75 (19.1)      |
| 34       | 1.218 (30.9)    | 1.258 (32.0)    | .75 (19.1)      |
| 35       | 1.250 (31.8)    | 1.290 (32.8)    | .75 (19.1)      |
| 36       | 1.281 (32.5)    | 1.321 (33.6)    | .75 (19.1)      |
| 37       | 1.312 (33.3)    | 1.352 (34.3)    | 1.00 (25.4)     |
| 38       | 1.343 (34.1)    | 1.383 (35.1)    | 1.00 (25.4)     |
| 39       | 1.375 (34.9)    | 1.415 (35.9)    | 1.00 (25.4)     |
| 40       | 1.406 (35.7)    | 1.446 (36.7)    | 1.00 (25.4)     |
| 41       | 1.437 (36.5)    | 1.477 (37.5)    | 1.00 (25.4)     |
| 42       | 1.468 (37.3)    | 1.508 (38.3)    | 1.00 (25.4)     |
| 43       | 1.500 (38.1)    | 1.540 (39.1)    | 1.00 (25.4)     |
| 44       | 1.531 (38.9)    | 1.571 (39.9)    | 1.00 (25.4)     |
| 45       | 1.562 (39.7)    | 1.602 (40.7)    | 1.00 (25.4)     |
| 46       | 1.593 (40.5)    | 1.633 (41.5)    | 1.00 (25.4)     |
| 47       | 1.625 (41.3)    | 1.665 (42.3)    | 1.00 (25.4)     |
| 48       | 1.656 (42.1)    | 1.696 (43.1)    | 1.00 (25.4)     |
| 49       | 1.687 (42.8)    | 1.727 (43.9)    | 1.00 (25.4)     |
| 50       | 1.718 (43.6)    | 1.758 (44.7)    | 1.00 (25.4)     |
| 51       | 1.750 (44.5)    | 1.790 (45.5)    | 1.00 (25.4)     |
| 52       | 1.781 (45.2)    | 1.821 (46.3)    | 1.00 (25.4)     |
| 53       | 1.812 (46.0)    | 1.852 (47.0)    | 1.00 (25.4)     |
| 54       | 1.843 (46.8)    | 1.883 (47.8)    | 1.00 (25.4)     |

1. Finish : Clear Anodize
2. Consult factory for other available lengths.
3. Metric dimensions (mm) are indicated in parentheses.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Glenair:

|                                   |                                   |                                   |                                   |                                   |                                   |                                   |                                   |                                   |
|-----------------------------------|-----------------------------------|-----------------------------------|-----------------------------------|-----------------------------------|-----------------------------------|-----------------------------------|-----------------------------------|-----------------------------------|
| <a href="#"><u>469-001-01</u></a> | <a href="#"><u>469-001-02</u></a> | <a href="#"><u>469-001-03</u></a> | <a href="#"><u>469-001-04</u></a> | <a href="#"><u>469-001-05</u></a> | <a href="#"><u>469-001-07</u></a> | <a href="#"><u>469-001-08</u></a> | <a href="#"><u>469-001-09</u></a> | <a href="#"><u>469-001-10</u></a> |
| <a href="#"><u>469-001-11</u></a> | <a href="#"><u>469-001-13</u></a> | <a href="#"><u>469-001-14</u></a> | <a href="#"><u>469-001-16</u></a> | <a href="#"><u>469-001-17</u></a> | <a href="#"><u>469-001-18</u></a> | <a href="#"><u>469-001-19</u></a> | <a href="#"><u>469-001-20</u></a> | <a href="#"><u>469-001-21</u></a> |
| <a href="#"><u>469-001-22</u></a> | <a href="#"><u>469-001-23</u></a> | <a href="#"><u>469-001-24</u></a> | <a href="#"><u>469-001-25</u></a> | <a href="#"><u>469-001-26</u></a> | <a href="#"><u>469-001-27</u></a> | <a href="#"><u>469-001-28</u></a> | <a href="#"><u>469-001-29</u></a> | <a href="#"><u>469-001-30</u></a> |
| <a href="#"><u>469-001-31</u></a> | <a href="#"><u>469-001-32</u></a> | <a href="#"><u>469-001-33</u></a> | <a href="#"><u>469-001-34</u></a> | <a href="#"><u>469-001-35</u></a> | <a href="#"><u>469-001-36</u></a> | <a href="#"><u>469-001-39</u></a> | <a href="#"><u>469-001-41</u></a> |                                   |