

MIL-C-26482

MIL-C-83723
Series I Bayonet

650DS001 B 16

Basic Part No.

Finish (Table IV)

Shell Size

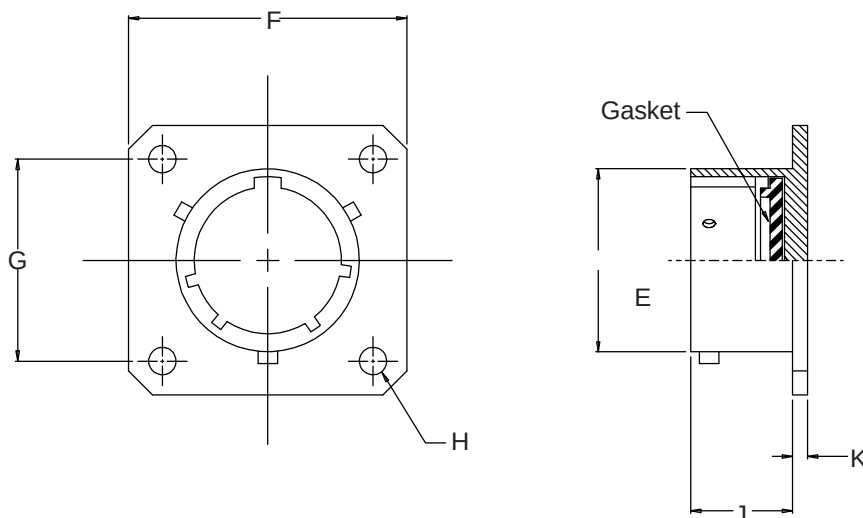


TABLE III: DIMENSIONS

Shell Size	E Dia	F Max	G	H Dia ±.010 (0.3)	J	K
08	.471 (12.0)	.828 (21.0)	.594 (15.1)	.120 (3.0)	.478 (12.1)	.062 (1.6)
10	.588 (14.9)	.954 (24.2)	.719 (18.3)	.120 (3.0)	.478 (12.1)	.062 (1.6)
12	.748 (19.0)	1.047 (26.6)	.812 (20.6)	.120 (3.0)	.478 (12.1)	.062 (1.6)
14	.873 (22.2)	1.141 (29.0)	.906 (23.0)	.120 (3.0)	.478 (12.1)	.062 (1.6)
16	.998 (25.3)	1.234 (31.3)	.969 (24.6)	.120 (3.0)	.478 (12.1)	.062 (1.6)
18	1.123 (28.5)	1.328 (33.7)	1.062 (27.0)	.120 (3.0)	.478 (12.1)	.062 (1.6)
20	1.248 (31.7)	1.453 (36.9)	1.156 (29.4)	.120 (3.0)	.572 (14.5)	.094 (2.4)
22	1.373 (34.9)	1.578 (40.1)	1.250 (31.8)	.120 (3.0)	.572 (14.5)	.094 (2.4)
24	1.498 (38.0)	1.703 (43.3)	1.375 (34.9)	.147 (3.7)	.605 (15.4)	.094 (2.4)

TABLE IV: STANDARD FINISHES

Finish Symbol	Finish
B	Cadmium Olive Drab
C	Anodize, Black
M	Electroless nickel
NF	500 hr Cadmium Olive Drab

1. For complete dimensions see Military Standard MS3115.
2. Metric dimensions (mm) are indicated in parentheses.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[650DS001B08](#) [650DS001B10](#) [650DS001B14](#) [650DS001B18](#) [650DS001B20](#) [650DS001B22](#) [650DS001B24](#)
[650DS001C12](#) [650DS001C22](#) [650DS001M08](#) [650DS001M10](#) [650DS001M12](#) [650DS001M14](#) [650DS001M20](#)
[650DS001M22](#) [650DS001NF10](#) [650DS001NF12](#) [650DS001NF14](#) [650DS001NF16](#) [650DS001NF18](#) [650DS001NF22](#)
[650DS001B12](#) [650DS001B16](#) [650DS001M16](#) [650DS001M18](#) [650DS001C20](#) [650DS001M24](#) [650DS001C14](#)
[650DS001C18](#)