


Series 811 Mighty Mouse High Density (HD) Pre-Wired Plug Connectors

811-001-16 and 811-001-06



Pre-Wired Plug Connectors Series 811 Mighty Mouse High Density plugs feature damage-resistant double-start ACME mating threads and integral shielding/overmolding platforms. These plugs are factory-terminated to insulated wire and backpotted with epoxy. The TwistPin contact system meets requirements of MIL-DTL-83513 and provides outstanding resistance to high levels of shock and vibration. Choose Type K general purpose Teflon® wire or Type J lightweight space-grade Tefzel® wire. 3A current rating, 600 VAC dielectric withstanding voltage.

How To Order										
Sample Part Number		811-001-06	MT	5-7	P	A	6	K	7	-18
Series		811-001-16 = Plug with Ratchet Mechanism 811-001-06 = Plug with Standard Coupling								
Material/Finish		See Material and Finish Table								
Shell Size - Insert Arr.		5-7 = 7 Contacts 8-30 = 30 Contacts	6-12 = 12 Contacts 9-42 = 42 Contacts	7-22 = 22 Contacts						
Contact Type		P = Pin Contacts	S = Socket Contacts							
Key Position		A = Normal	Alternate Key Positions: B, C, D, E, F							
Wire size		6 = #26 AWG 0 = #30 AWG (Wire Type J, color code 1 or 7 only)	8 = #28 AWG (color code 1 or 7 only)							
Wire Type		K = M22759/11	J = M22759-33	E = NEMA HP3-EB						
Wire Color		1 = White	5 = Color code per MIL-STD-681 (striped)*		7 = 10 Solid colors, repeating					
Wire Length (inches)		12, 18, 36, 72 Specify any length from 2 inches to 144 inches								

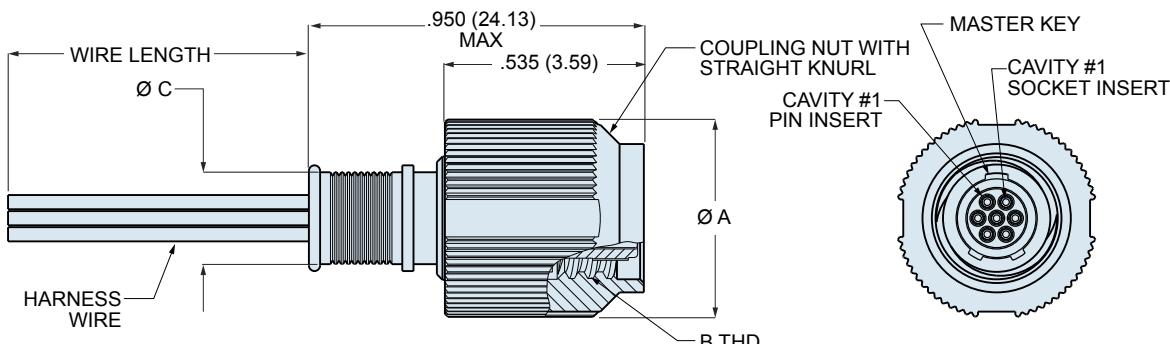

*Size 28 AWG and Size 30 AWG J type wire not available in striped color code 5

Material and Finish		
Code	Material	Finish
ME	Aluminum	Electroless Nickel
ZNU	Aluminum	Zinc-Nickel-PTFE with Black Chromate
MT	Aluminum	Nickel-PTFE
ZR	Aluminum	Zinc-Nickel with Black Chromate
Z1	Stainless Steel	Passivated

ZR plating is RoHS compliant and non-reflective.
ZNU plating is non-reflective and passes 1,000 hours salt spray testing

Shell Size	Ø A		B Thread	Ø C	
	In.	mm.		In.	mm.
5	.540	13.72	.3125-.05P-.1L-2B	.246	6.25
6	.600	15.24	.375-.05P-.1L-2B	.286	7.26
7	.730	18.54	.4375-.05P-.1L-2B	.391	9.93
8	.800	20.32	.5000-.05P-.1L-2B	.443	11.25
9	.862	21.89	.5625-.05P-.1L-2B	.498	12.65

Dimensions in Inches (millimeters) are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Glenair](#):

[811-001-06ME8-30SA6J7-36](#)