


Series 970 PowerTrip™ Connectors and Accessories

Contacts and Tools

Crimp Tools



HAND CRIMP TOOL AND POSITIONER FOR #12 AND #16 CONTACTS

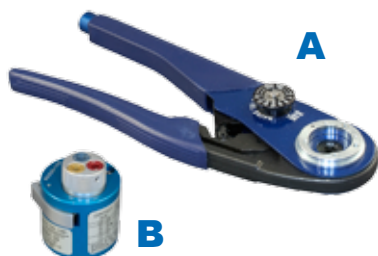

A Crimp tool for use with size #16 and #12 Series 970 pin and socket contacts. Use with turret-type positioner 859-032. 9.75 inches OAL, 1.25 pounds.

B Positioner for use with size #12 and #16 contacts. Rotate turret head to blue position for #16 contact termination, yellow position for #12 contacts.

Figure	Part Number	Military Part Number	Daniels Part Number
A	809-136	M22520/1-01	AF8
B	859-032	M22520/1-02	TH1A

PNEUMATIC CRIMP TOOL FOR #8, #4 AND #1/0 CONTACTS




C Bench mount pneumatic crimp tool. Heavy duty, four-indent crimp termination. Attach to air supply with quick-disconnect fitting or install 1/4 NPT fitting into tapped port. 90-120 psi air supply. Requires die assemblies and locators, sold separately. Hand actuate with push-button valve trigger on handle. Steel with black wrinkle enamel coating. 13 inches overall length, 9.2 inches tall, 17 pounds (7.7 Kg).

D Indenter Die Assembly. Precision four-indent die with hardened tool steel indenters, stainless steel housing. Separate die assembly required for each contact size.

E Locator. Aluminum locator positions contact at correct depth for crimping. Separate locator required for each contact size.



Figure	Contact Size	Description	Part Number	Military Part Number	Daniels Part Number
C	—	Pneumatic Crimper	859-025	M22520/23-01	WA23
D	8	Die Assembly	859-026	M22520/23-02	WA23-2
D	4	Die Assembly	859-027	M22520/23-04	WA23-4
D	1/0	Die Assembly	859-028	M22520/23-05	WA23-5
E	8	Locator	859-029	M22520/23-09	WA23-9
E	4	Locator	859-030	M22520/23-11	WA23-11
E	1/0	Locator	859-031	M22520/23-13	WA23-13

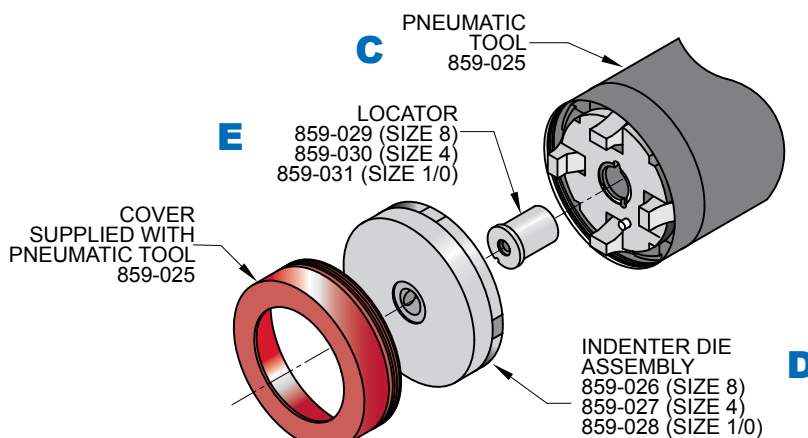

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[859-025](#) [859-028](#) [859-031](#)