



FA04390

Fiber Optic Test Cable for 050-113 Media Converter


D38999 Series III Type Connector Interface



How To Order

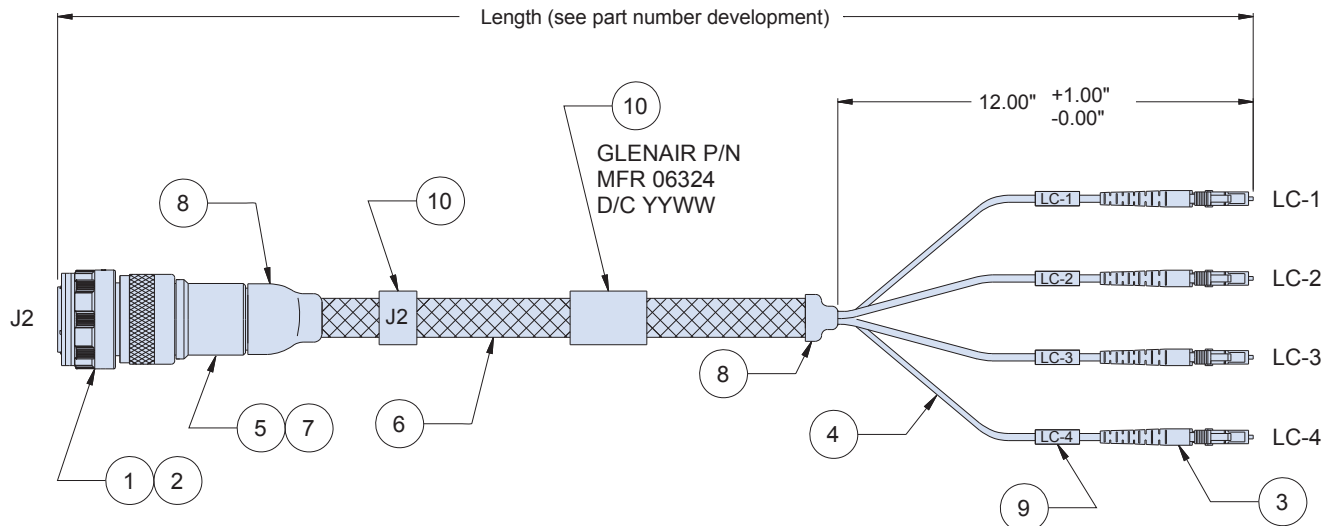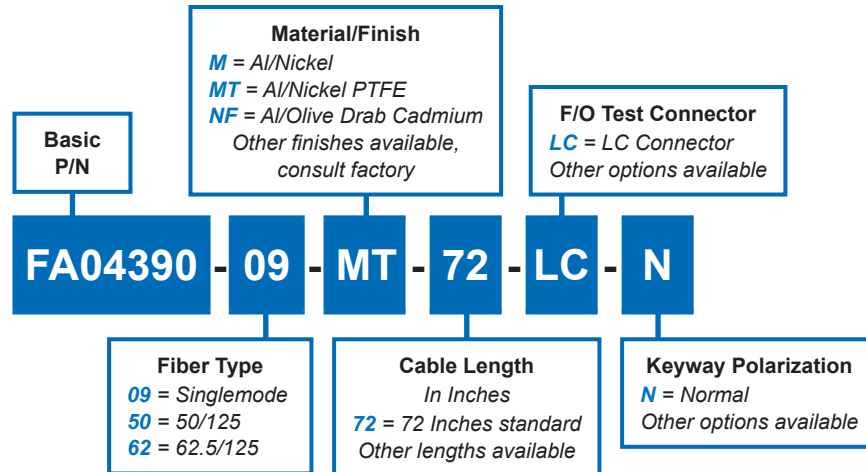

Connection Diagram

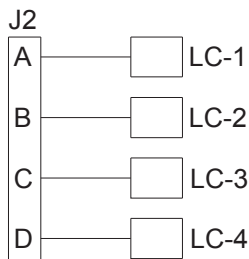

Standard Tolerance	
Length	Tolerance
5 in – 2 ft	+1 in -0
2 to 10 ft	+3 in -0
10 to 50 ft	+6 in -0
50 to 100 ft	+1 ft -0
100 ft and up	+2 ft -0

Diagram Key	
Callout	Description
1, 2	180-091 Fiber Optic plug connector / four 181-001 pin termini
3	Four single-channel LC fiber optic connectors (other options available, consult factory)
4	Simplex high-temperature fiber
5	440HS030 Glenair Backshell
6	Nomex braid
7	Band-Master ATS® shield termination strap
8	Heat shrink
9	Heat shrink
10	ID marker (marked with Glenair name, CAGE code and date code as indicated)

Notes

- Optical performance: insertion loss to be less than 1.5 dB when measured at 850 nm wavelength for Multimode and 1310 nm wavelength for Singlemode.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[FA04390-50-M-72-LC-N](#)