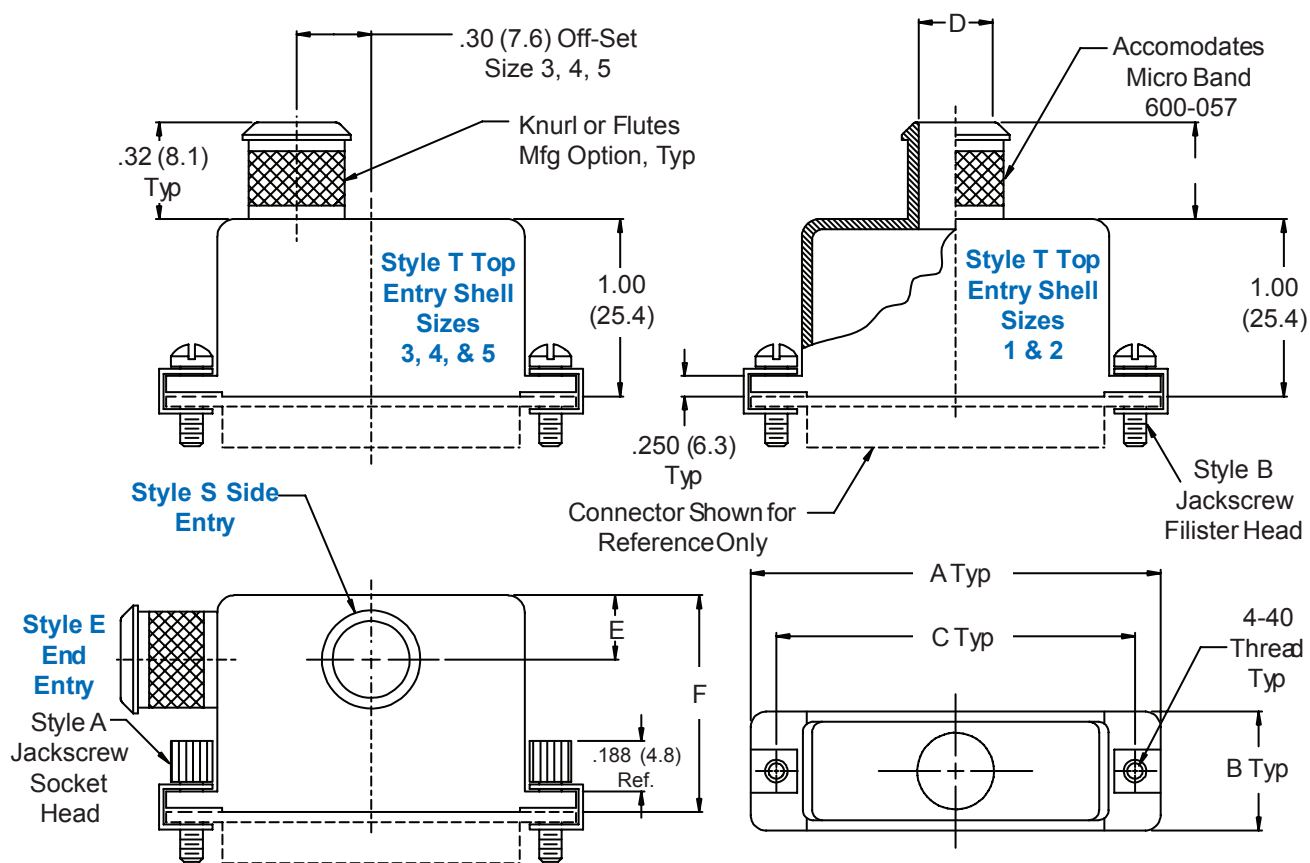


557-283 D-Subminiature Lightweight Solid EMI/RFI Banding Backshell

557 T 283 M 3 B-06 B
 Basic Part No. _____
 Cable Entry Style _____
 T = Top Entry
 E = End Entry
 S = Side Entry
 Basic Part No. _____
 Finish Symbol (Page 3) _____
 B = Band Supplied (600-057), Omit for None
 Entry Size (Table II)
 Jackscrew Style
 A = Male Socket Head Screw With Clip
 B = Male Screw With Clip
 H = Hex Head Jackscrew With Clip
 Shell Size (Table I)


TABLE I: SHELL SIZE & CONNECTOR INTERFACE

Shell Size	A Max	B	C ±.005 (.1)
1	1.25 (31.8)	.530 (13.5)	.984 (25.0)
2	1.58 (40.1)	.530 (13.5)	1.312 (33.3)
3	2.13 (54.1)	.530 (13.5)	1.852 (47.0)
4	2.77 (70.4)	.530 (13.5)	2.500 (63.5)
5	2.68 (68.1)	.660 (16.8)	2.406 (61.1)

TABLE II: CABLE ENTRY & BACKSHELL DIMS

Entry Size	D	E	F
04	.250 (6.4)	.250 (6.4)	1.25 (31.8)
05	.312 (7.9)	.281 (7.1)	1.38 (35.1)
06	.375 (9.5)	.312 (7.9)	1.38 (35.1)
07	.437 (11.1)	.344 (8.7)	1.50 (38.1)
08*	.500 (12.7)	.375 (9.5)	1.50 (38.1)

* Available in shell size 5 only.

Metric dimensions (mm) are indicated in parentheses.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[557T283M3A07](#) [557T283M1A04B](#) [557T283M3A07B](#) [557T283M4A07B](#) [557T283M4B07B](#) [557S283B5B06](#)
[557T283M2A04B](#) [557T283M2A05B](#) [557T283M2B04B](#) [557T283M3B04B](#) [557T283M3B07B](#) [557T283NF5B08B](#)
[557T283M1B04B](#) [557T283B3A07B](#) [557T283M1H07B](#) [557T283NF2B05B](#) [557T283NF2B07B](#) [557T283NF4B06B](#)
[557T283NF5B05B](#) [557E283M1B04B](#) [557E283M3H06](#) [557T283J1A04B](#) [557T283M2A07B](#) [557T283NF3B04B](#)
[557T283M2B06](#) [557T283M2B06B](#) [557T283NF2A07B](#) [557T283NF1A06](#)