

**Series 802 “Aqua Mouse”
Cable Plugs
802-001 & 802-003**



Series 802
Submersible

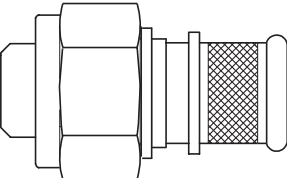
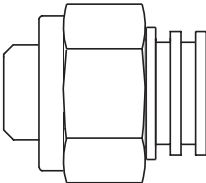
How to Order Series 802 Cable Plugs

Series 802 “Aqua Mouse” Cable Plugs are available in two styles:

Integral Band Platform for attachment of cable shields.

Integral Molding Platform for unshielded cable.

How To Order Series 802 Cable Plugs

Series	Shell Style	Shell Material / Finish	Shell Size / Insert Arrangement	Contact Type	Shell Key
802-001 Banding Platform 	06 Plug	Z1 Stainless Steel, with Passivated Finish	6-4 4 Contacts  6-7 7 Contacts  9-19 19 Contacts 	P Pin S Socket	N Normal Alternate Key Positions X Y Z
802-003 Molding Platform 					

Part Number Example

802-001

—06

Z1

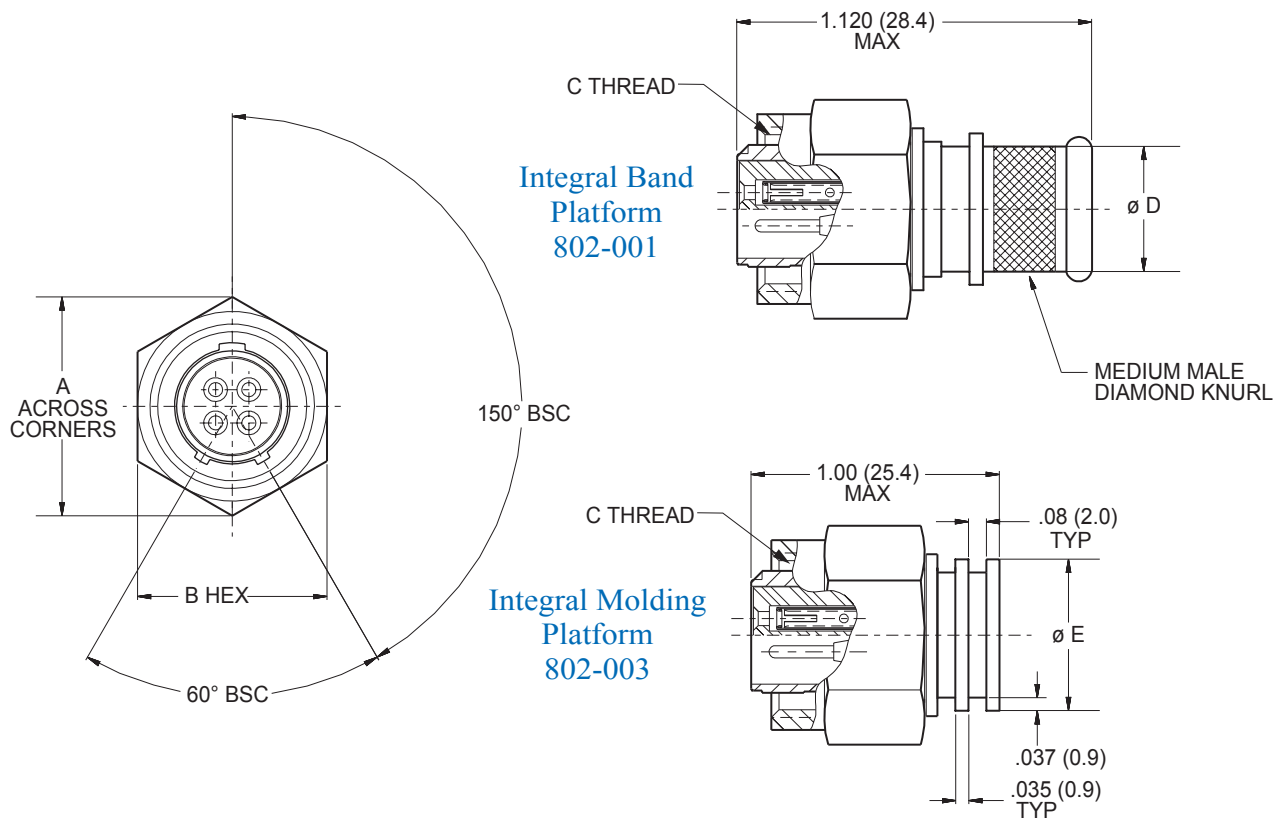
9—19

P

N

Series 802 Cable Plug Dimensions

Series 802 Cable Plug Dimensions



Series 802 Cable Plug Dimensions

Layout	A	B Hex	C Thread	Ø D	Ø E
6-4	.69 (17.5)	.625 (15.9)	.5625-20 UN-2B	.30 (7.6)	.375 (9.5)
6-7	.69 (17.5)	.625 (15.9)	.5625-20 UN-2B	.30 (7.6)	.375 (9.5)
9-19	.94 (23.9)	.813 (20.7)	.750-20 UNEF-2B	.52 (13.2)	.595 (15.1)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[802-003-06Z16-7SY](#) [802-001-06Z16-7PN](#) [802-001-06Z16-4SN](#)