

450-001

Qwik-Ty® Strain Relief - Connector Designator L

Rotatable Coupling (Straight, 45° and 90° Elbows)

CONNECTOR DESIGNATOR

L

Product Series — 450 L S 001 M 16 G

Connector Designator —


Angle and Profile —
A = 90°
B = 45°
S = Straight

Ground Lug (Omit for none)

Shell Size (Table I)

Finish (Table II)

Basic Part Number

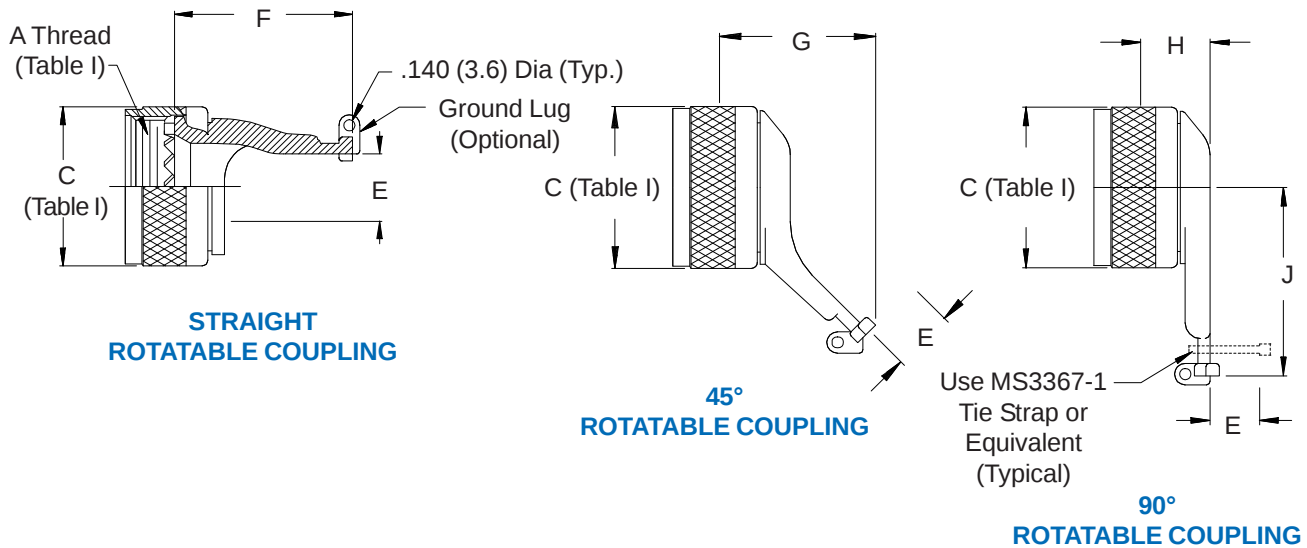

See inside back cover fold-out or pages 13 and 14 for Tables I and II.

TABLE III: DIMENSIONS						
Shell Size	E Cable Entry	F Max	G Max	H Max	J Max	
08	.269 (6.8)	.866 (22.0)	1.066 (27.1)	.464 (11.8)	.890 (22.6)	
10	.397 (10.1)	.866 (22.0)	1.066 (27.1)	.496 (12.6)	.950 (24.1)	
12	.511 (13.0)	.926 (23.5)	1.066 (27.1)	.535 (13.6)	1.070 (27.2)	
14	.636 (16.2)	1.106 (28.1)	1.188 (30.2)	.574 (14.6)	1.330 (33.8)	
16	.761 (19.3)	1.106 (28.1)	1.224 (31.1)	.590 (15.0)	1.390 (35.3)	
18	.850 (21.6)	1.176 (29.9)	1.224 (31.1)	.685 (17.4)	1.480 (37.6)	
20	.975 (24.8)	1.306 (33.2)	1.224 (31.1)	.685 (17.4)	1.660 (42.2)	
22	1.100 (27.9)	1.426 (36.2)	1.224 (31.1)	.716 (18.2)	1.850 (47.0)	
24	1.225 (31.1)	1.556 (39.5)	1.224 (31.1)	.755 (19.2)	1.910 (48.5)	

1. Cable Entry is defined as the accommodation entry for the wire bundle or cable. Dimensions are not intended for inspection criteria.
2. Metric dimensions (mm) are indicated in parentheses.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[450LA001NF14](#) [450LS001N12](#) [450LS001N18G](#) [450LS001NF12](#) [450LS001NF22](#) [450LA001N12G](#) [450LA001N14G](#)
[450LA001NF08](#) [450LA001NF10](#) [450LB001N24G](#) [450LS001NF10](#)