




600F005

Plug and Receptacle Holder

MIL-DTL-27599, MIL-DTL-38999 Series I

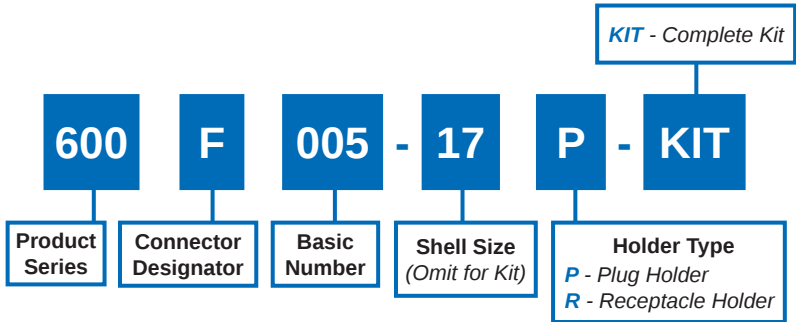

NO POLARIZATION REQUIRED

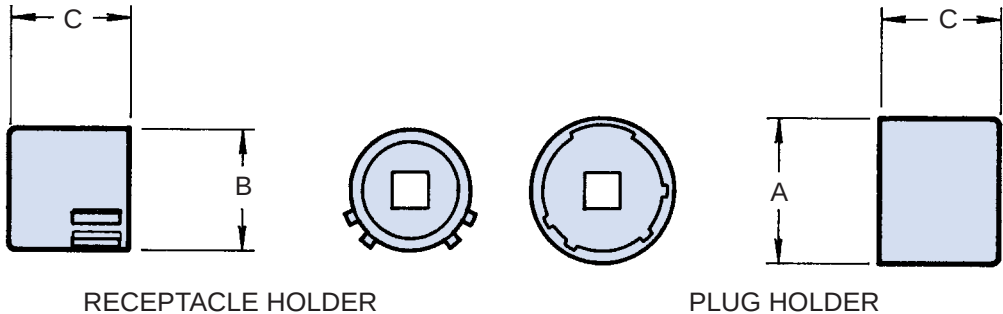


TABLE I: Dash Number, Torque and Dimensions

| Dash No. | Torque Max (In/lbs) | A Dia Max    | B Dia Max    | C Dim Max    |
|----------|---------------------|--------------|--------------|--------------|
| 09       | 40                  | .577 (14.7)  | .438 (11.1)  | 1.031 (26.2) |
| 11       | 40                  | .709 (18.0)  | .566 (14.4)  | 1.031 (26.2) |
| 13       | 40                  | .829 (21.1)  | .678 (17.2)  | 1.031 (26.2) |
| 15       | 40                  | .954 (24.2)  | .803 (20.4)  | 1.031 (26.2) |
| 17       | 40                  | 1.107 (28.1) | .928 (23.6)  | 1.031 (26.2) |
| 19       | 40                  | 1.190 (30.2) | 1.033 (26.2) | 1.031 (26.2) |
| 21       | 80                  | 1.315 (33.4) | 1.158 (29.4) | 1.031 (26.2) |
| 23       | 80                  | 1.440 (36.6) | 1.283 (32.6) | 1.031 (26.2) |
| 25       | 80                  | 1.565 (39.8) | 1.408 (35.8) | 1.031 (26.2) |

| APPLICATION NOTES                                                                                  |
|----------------------------------------------------------------------------------------------------|
| 1. Metric dimensions (mm) are indicated in parentheses.                                            |
| 2. Material: Case hardened carbon steel with electroless nickel finish.                            |
| 3. Receptacle and plug holder drives: 1/4" - Shell sizes 08, 10, 12; 3/8" - Shell sizes 14 and up. |

Dimensions in inches (millimeters) and are subject to change without notice.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[600F005-11P](#) [600F005-11R](#) [600F005-17R](#) [600F005-21R](#) [600F005-19P](#) [600F005-25P](#) [600F005-23R](#) [600F005-19R](#)