


Series 80 Mighty Mouse Replacement O-Rings For Jam Nut Receptacles



Accessories

800 and 801 Replacement O-rings for Mighty Mouse jam nut receptacles

Replace lost or damaged O-rings with standard fluorosilicone O-rings. Or, choose EPDM O-rings for improved resistance to hydraulic fluids. Upgrade to silver-filled conductive O-rings for improved EMI protection.

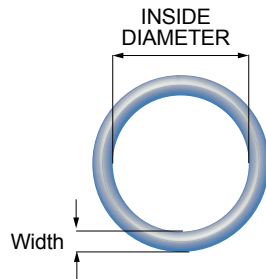

O-rings for Series 800 Jam Nut Receptacles

Shell Size	Part Number				Dimensions			
	Fluoro-silicone	EPDM	Conductive Silicone Cho-Seal 1285	Conductive Fluorosilicone Cho-Seal 1298	Inside Diameter		Width	
					In.	mm.	In.	mm.
-05	809-067-05F	809-067-05E	249-003-800-05-B	249-003-800-05-C	.364	9.25	.045	1.14
-06	809-067-06F	809-067-06E	249-003-800-06-B	249-003-800-06-C	.426	10.82	.050	1.27
-07	809-067-07F	809-067-07E	249-003-800-07-B	249-003-800-07-C	.489	12.42	.055	1.40
-08	809-067-08F	809-067-08E	249-003-800-08-B	249-003-800-08-C	.588	14.94	.051	1.30
-09	809-067-09F	809-067-09E	249-003-800-09-B	249-003-800-09-C	.614	15.60	.070	1.78
-10	809-067-10F	809-067-10E	249-003-800-10-B	249-003-800-10-C	.709	18.01	.079	2.01
-12	809-067-12F	809-067-12E	249-003-800-12-B	249-003-800-12-C	.801	20.35	.070	1.78
-14	809-067-14F	809-067-14E	249-003-800-14-B	249-003-800-14-C	.926	23.52	.070	1.78
-15	809-067-15F	809-067-15E	249-003-800-15-B	249-003-800-15-C	.989	25.12	.070	1.78

O-rings for Series 801 Jam Nut Receptacles

Shell Size	Part Number				Dimensions			
	Fluoro-silicone	EPDM	Conductive Silicone Cho-Seal 1285	Conductive Fluorosilicone Cho-Seal 1298	Inside Diameter		Width	
					In.	mm.	In.	mm.
-05	809-054-05F	809-054-05E	249-003-801-05-B	249-003-801-05-C	.394	10.01	.047	1.19
-06	809-054-06F	809-054-06E	249-003-801-06-B	249-003-801-06-C	.459	11.66	.049	1.24
-07	809-054-07F	809-054-07E	249-003-801-07-B	249-003-801-07-C	.578	14.68	.040	1.02
-08	809-054-08F	809-054-08E	249-003-801-08-B	249-003-801-08-C	.578	14.68	.040	1.02
-09	809-054-09F	809-054-09E	249-003-801-09-B	249-003-801-09-C	.650	16.51	.045	1.14
-10	809-054-10F	809-054-10E	249-003-801-10-B	249-003-801-10-C	.709	18.01	.049 (non-cond.) .043 (conductive)	1.24 1.09
-11	809-054-11F	809-054-11E	N/A	N/A	.780	19.81	.047	1.19
-13	809-054-13F	809-054-13E	249-003-801-13-B	249-003-801-13-C	.894	22.71	.047	1.19
-14	809-054-14F	809-054-14E	N/A	N/A	.945	24.00	.047	1.19
-15	809-054-15F	809-054-15E	N/A	N/A	1.024	26.01	.047	1.19
-16	809-054-16F	809-054-16E	249-003-801-16-B	249-003-801-16-C	1.086	27.58	.040	1.02
-17	809-054-17F	809-054-17E	249-003-801-17-B	249-003-801-17-C	1.142	29.01	.043	1.09
-18	809-054-18F	809-054-18E	N/A	N/A	1.201	30.51	.047	1.19
-19	809-054-19F	809-054-19E	N/A	N/A	1.257	31.93	.047	1.19
-21	809-054-21F	809-054-21E	249-003-801-21-B	249-003-801-21-C	1.417	35.99	.047	1.19
-23	809-054-23F	809-054-23E	249-003-801-23-B	249-003-801-23-C	1.530	38.86	.047	1.19


Dimensions in Inches (millimeters) are subject to change without notice.



Series 80 Mighty Mouse Replacement O-Rings For Jam Nut Receptacles


802 Replacement O-rings for Mighty Mouse receptacles

These Viton® O-rings fit Series 802 "AquaMouse" rear panel mount jam nut connector flanges.

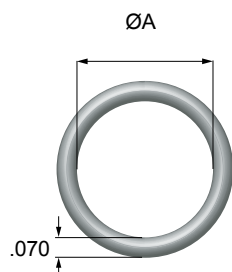

X

These Viton® Piston O-rings fit Series 802 "AquaMouse".

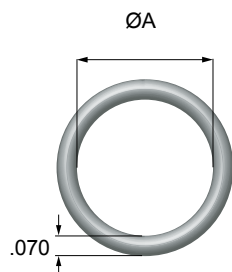

Flange O-rings for Series 802 Jam Nut and Square Flange Receptacles


Shell Size	Jam Nut Flange Style				Square Flange Style			
	Part Number	O-Ring Size	Ø A Inside Dia.		Part Number	O-Ring Size	Ø A Inside Dia.	
			In.	mm.			In.	mm.
-05	809-165-05	2-015	.551	14.00	809-165-35	2-012	.364	9.25
-06	809-165-06	2-017	.676	17.17	809-165-36	2-014	.489	12.42
-07	809-165-07	2-018	.739	18.77	809-165-37	2-015	.551	14.00
-08	809-165-08	2-019	.801	20.35	809-165-38	2-016	.614	15.60
-09	809-165-09	2-020	.864	21.95	809-165-39	2-017	.676	17.17
-10	809-165-10	2-021	.926	23.52	809-165-40	2-018	.739	18.77
-12	809-165-12	2-022	.989	25.12	809-165-42	2-019	.801	20.35
-14	809-165-14	2-025	1.176	29.87	809-165-44	2-022	.989	25.12
-15	809-165-15	2-026	1.239	31.47	809-165-45	2-023	1.051	26.70
-21	809-165-21	2-030	1.614	41.00	809-165-51	2-028	1.364	34.65

Piston O-rings for Series 802

Shell Size	Part Number	O-Ring ID x Width Dimensions		Shell Size	Part Number	O-Ring ID x Width Dimensions	
		In.	mm.			In.	mm.
-05	809-209-05	.208 x .070	5.28 x 1.78	10	809-209-10	.551 x .070	14.00 x 1.78
-06	809-209-06	.270 x .070	6.86 x 1.78	12	809-209-12	.614 x .070	15.60 x 1.78
-07	809-209-07	.364 x .070	9.24 x 1.78	14	809-209-14	.801 x .070	20.34 x 1.78
-08	809-209-08	.384 x .070	9.75 x 1.78	15	809-209-15	.864 x .070	21.94 x 1.78
-09	809-209-09	.489 x .070	12.42 x 1.78	21	809-209-21	1.051 x .070	26.70 x 1.78

803 Replacement O-rings for Mighty Mouse jam nut receptacles

Replace lost or damaged O-rings with standard fluorosilicone O-rings. Or, choose EPDM O-rings for improved resistance to hydraulic fluids.

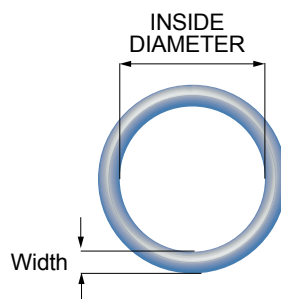

O-rings for Series 803 Jam Nut Receptacles

Shell Size	Part Number		Dimensions			
	Fluoro-silicone	EPDM	Inside Diameter		Width	
			In.	mm.	In.	mm.
-05	809-189-05F	809-189-05E	.394	10.01	.047	1.19
-06	809-189-06F	809-189-06E	.459	11.66	.049	1.24
-07	809-189-07F	809-189-07E	.578	14.68	.040	1.02
-08	809-189-08F	809-189-08E	.650	16.51	.045	1.14
-09	809-189-09F	809-189-09E	.650	16.51	.045	1.14
-10	809-189-10F	809-189-10E	.780	19.81	.047	1.19
-12	809-189-12F	809-189-12E	.894	22.71	.047	1.19
-14	809-189-14F	809-189-14E	1.086	27.58	.040	1.02
-15	809-189-15F	809-189-15E	1.142	29.01	.043	1.09

Dimensions in Inches (millimeters) are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[809-035Z107](#) [809-035Z108](#) [809-035NF22W](#) [809-035NF02W](#) [809-035M23W](#) [809-035Z109W](#) [809-035ZN16](#) [809-035Z118W](#) [809-035Z104W](#) [809-035NF05W](#) [809-035ZNU23W](#) [809-083-06G5-08](#) [809-083-06G5-02](#) [809-083-09G3-16](#) [809-087-09G3-18](#) [809-087-08G6-SK](#) [809-087-06G5-08](#) [809-083-06](#) [809-087-07G3-15](#) [809-087-06G1-08](#) [809-087-06G2-16](#) [809-083-10G3-18](#) [809-087-07G6-SK](#) [809-084-10G3-03](#) [809-087-10G3-10](#) [809-083-09G6-SK](#) [809-054-10F](#) [809-067-06F](#) [809-035Z109](#) [809-035Z111](#) [809-035Z115](#) [809-035M04W](#) [809-035M05W](#) [809-035M07](#) [809-035M08](#) [809-035M09W](#) [809-035M14W](#) [809-035ZN08W](#) [809-035M07W](#) [809-035M09](#) [809-035M11W](#) [809-035NF08W](#) [809-035ZN04W](#) [809-035M08W](#) [809-035NF07W](#) [809-035ZN09W](#) [809-035NF03W](#) [809-035NF19W](#) [809-035M18W](#) [809-035Z116W](#) [809-035M15W](#) [809-035NF14W](#) [809-035M10W](#)