



Basic Part No.

TG60 - 15

Shell Size

NOTES

1. Metric dimensions (mm) are indicated in parentheses.
2. Material: Aluminum alloy with electroless nickel finish.

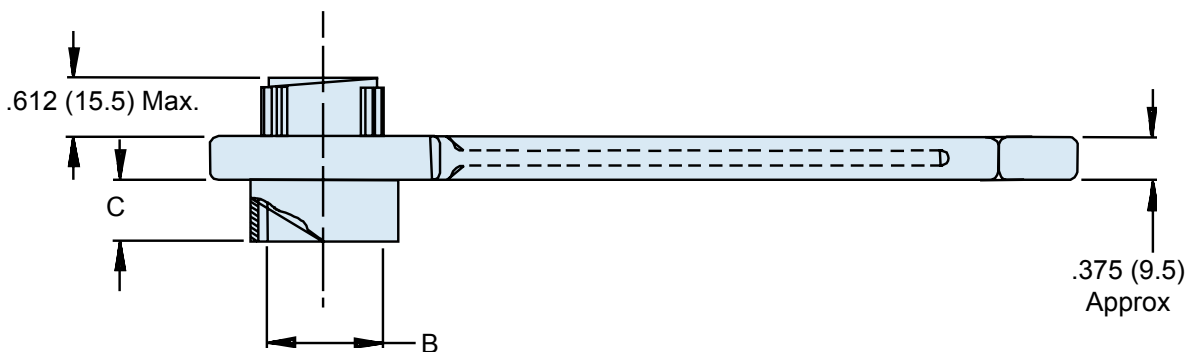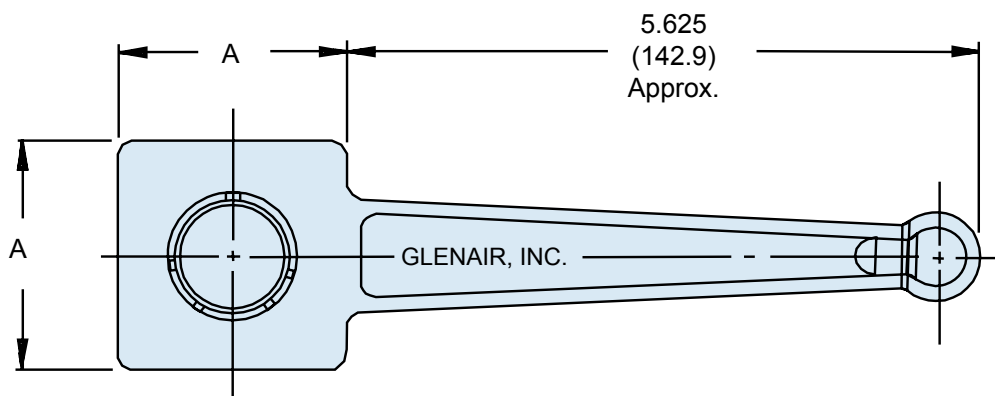

Shell Size	A Dim. Ref.	B Dia. Ref.	C Max
9	1.250 (31.8)	.442 (11.2)	.647 (16.4)
11	1.250 (31.8)	.570 (14.5)	.647 (16.4)
13	1.250 (31.8)	.687 (17.4)	.647 (16.4)
15	2.000 (50.8)	.812 (20.6)	.647 (16.4)
17	2.000 (50.8)	.937 (23.8)	.647 (16.4)
19	2.000 (50.8)	1.042 (26.5)	.647 (16.4)
21	2.000 (50.8)	1.167 (29.6)	.617 (15.7)
23	2.000 (50.8)	1.292 (32.8)	.617 (15.7)
25	2.000 (50.8)	1.417 (36.0)	.617 (15.7)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[TG60-11](#) [TG60-13](#) [TG60-13-39](#) [TG60-15](#) [TG60-15-39](#) [TG60-17](#) [TG60-17-39](#) [TG60-19](#) [TG60-19-39](#) [TG60-21](#)
[TG60-21-39](#) [TG60-23](#) [TG60-23-39](#) [TG60-25](#) [TG60-25-39](#) [TG60-9](#) [TG60-9-39](#) [TG60-KIT](#)