

TG61

MIL-C-81511 Series I and III

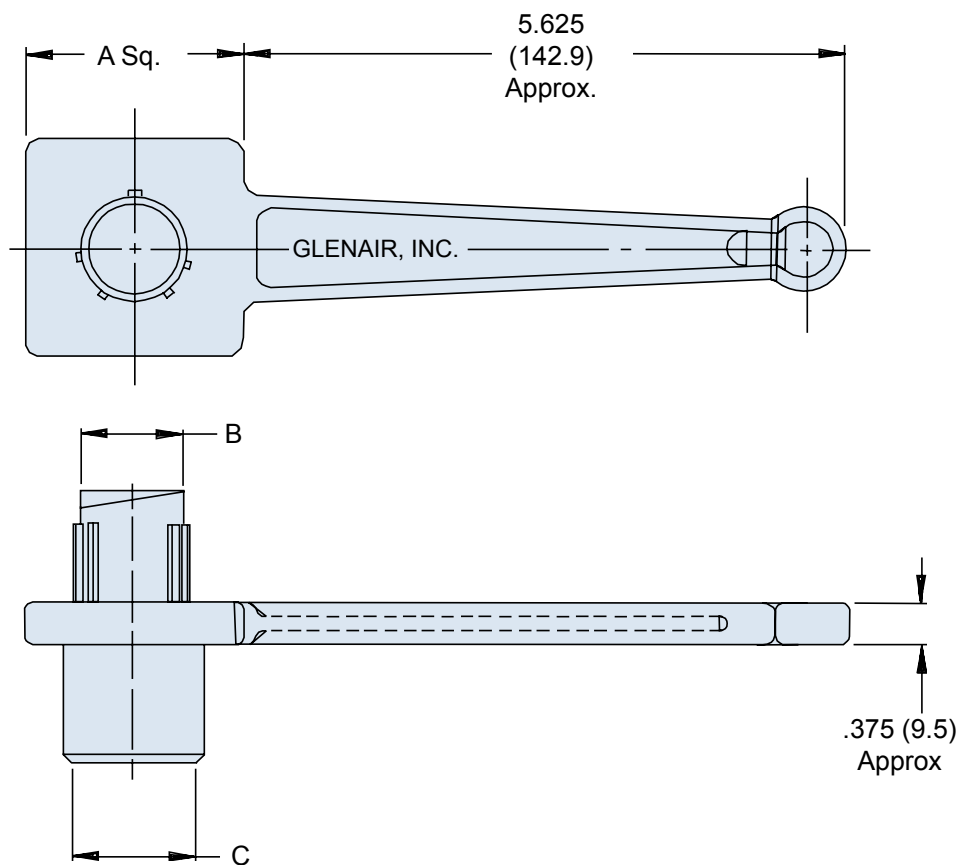
Connector Wrench

TG48

-

20

1

Basic Part
NumberShell
SizePolarization
1, 2, 3, 4, 5, 6
(Omit for Normal)

Shell Size	A Dim. ± .062 (1.6)	B Dia. Ref.	C Dia. Ref.
08	1.250 (31.8)	.378 (9.6)	.407 (10.3)
10	1.250 (31.8)	.503 (12.8)	.532 (13.5)
14	2.000 (50.8)	.751 (19.1)	.782 (19.9)
16	2.000 (50.8)	.877 (22.3)	.908 (23.1)
18	2.000 (50.8)	1.001 (25.4)	1.032 (26.2)
20	2.000 (50.8)	1.126 (28.6)	1.157 (29.4)
22	2.750 (69.9)	1.251 (31.8)	1.282 (32.6)
24	2.750 (69.9)	1.376 (35.0)	1.407 (35.7)

APPLICATION NOTES

1. Metric dimensions (mm) are indicated in parentheses.
2. Material: Aluminum alloy with electroless nickel finish.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[MS3482-18-1](#) [MS3482-10-4](#) [MS3482-16-4](#) [MS3482-18-6](#) [MS3482-14-1](#) [MS3482-10-5](#) [MS3482-18-3](#) [MS3482-18-4](#)
[MS3482-8-2](#) [MS3482-10-1](#) [MS3482-14-4](#) [MS3482-16-3](#) [MS3482-18-5](#) [MS3482-14-2](#) [MS3482-10-3](#) [MS3482-16-1](#)
[MS3482-14-3](#) [MS3482-18-2](#)