

TG90

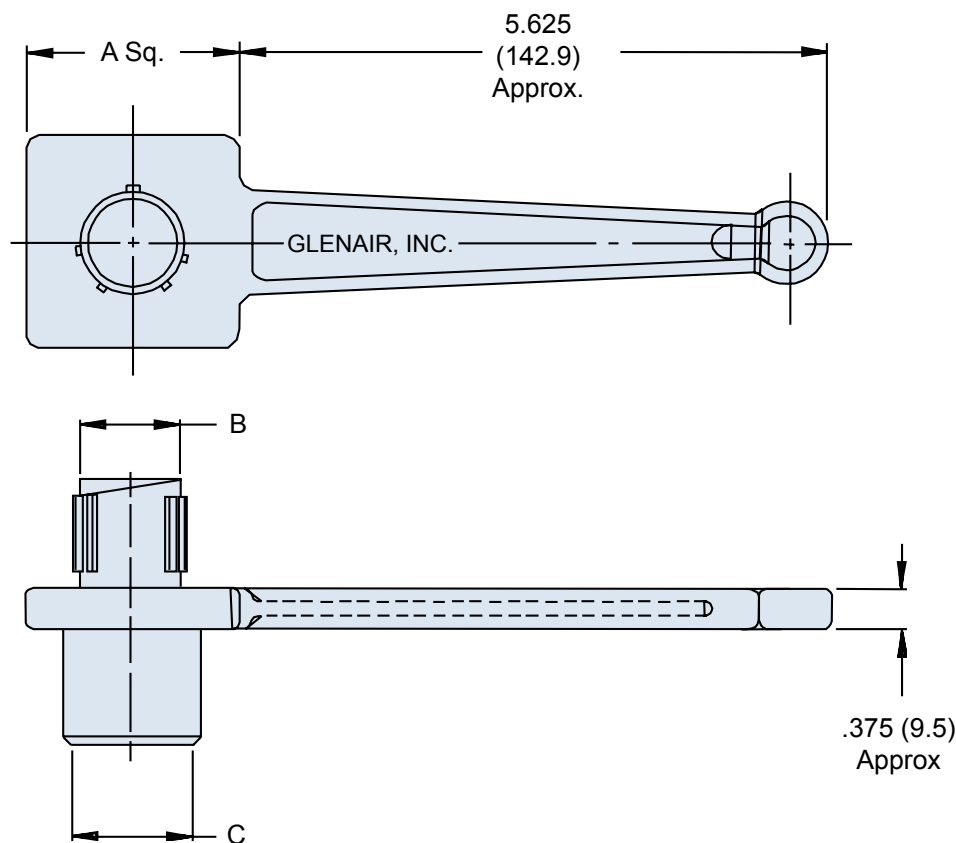
MIL-C-38999 Series III

Connector Wrench

TG90

- 15

A

Basic Part
NumberShell
SizePolarization
A, B, C, D, E
(Omit for Normal)

Shell Size	A Dim. ± .062 (1.6)	B Dia. Ref.	C Dia. Ref.
09	1.250 (31.8)	.438 (11.1)	.441 (11.2)
11	1.250 (31.8)	.566 (14.4)	.569 (14.5)
13	1.250 (31.8)	.678 (17.2)	.682 (17.3)
15	2.000 (50.8)	.802 (20.4)	.811 (20.6)
17	2.000 (50.8)	.928 (23.6)	.931 (23.6)
19	2.000 (50.8)	1.032 (26.2)	1.037 (26.3)
21	2.000 (50.8)	1.155 (29.3)	1.162 (29.5)
23	2.750 (69.9)	1.283 (32.6)	1.288 (32.7)
25	2.750 (69.9)	1.407 (35.7)	1.411 (35.8)

APPLICATION NOTES

1. Metric dimensions (mm) are indicated in parentheses.
2. Material: Aluminum alloy with electroless nickel finish.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[TG90-11](#) [TG90-11B](#) [TG90-11C](#) [TG90-11D](#) [TG90-11E](#) [TG90-13](#) [TG90-13A](#) [TG90-13C](#) [TG90-13E](#) [TG90-15](#)
[TG90-15B](#) [TG90-15C](#) [TG90-15D](#) [TG90-15E](#) [TG90-17](#) [TG90-17A](#) [TG90-17B](#) [TG90-17C](#) [TG90-17D](#) [TG90-17E](#)
[TG90-19](#) [TG90-19A](#) [TG90-19B](#) [TG90-19C](#) [TG90-19D](#) [TG90-19E](#) [TG90-21A](#) [TG90-21B](#) [TG90-21D](#) [TG90-21E](#)
[TG90-23](#) [TG90-23B](#) [TG90-23D](#) [TG90-23E](#) [TG90-25](#) [TG90-25A](#) [TG90-25B](#) [TG90-25C](#) [TG90-25D](#) [TG90-25E](#)
[TG90-9](#) [TG90-9B](#) [TG90-9D](#) [TG90-9E](#) [TG90-21](#)