


# PB-105M

## 4560 TIE-POINT, EXTERNALLY POWERED SOLDERLESS BREADBOARD

### Applications

The PB-105M Externally Powered Solderless Breadboard is a great way to prototype low frequency or DC powered circuits. It is ideal for:

- Educational labs
- Hobbyists

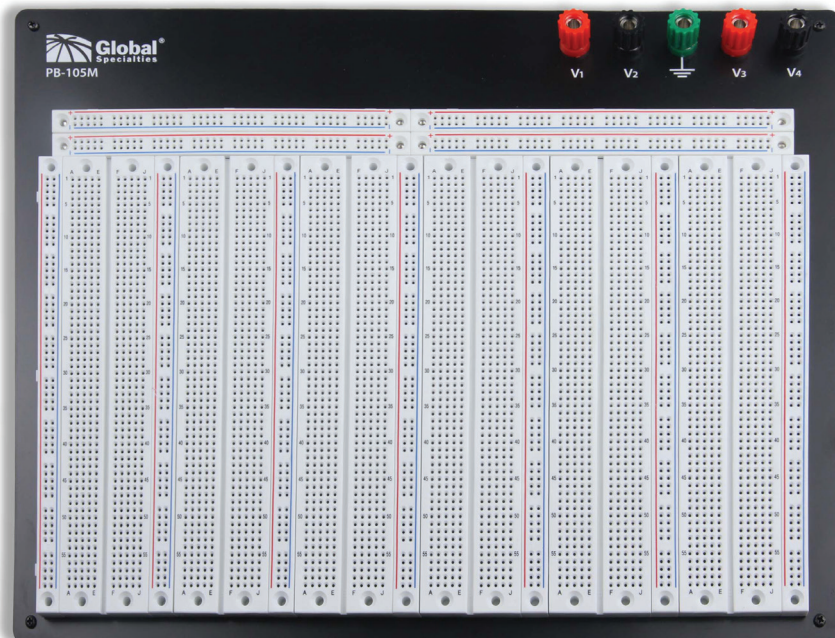

### Features

- Comes fully assembled
- Externally powered
- 4560 Tie-points
- 5 Binding posts
- 19 mm standard spaced binding posts
- ABS plastic body
- Square hole style
- Fits 0.4-0.7 mm wire diameter
- Fits 42 total 16-pin ICs
- Nickel plated phosphor bronze spring clip contacts
- Rubber feet
- Aluminum back plate
- Measures 30.5 x 24 x 2.7 cm
- Weighs 900 g
- Maximum current capacity of 1.5 A at 36 V
- RoHS compliant
- Three-year warranty

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Global Specialties:](#)

[PB-105M](#)