



Quality Products. Service Excellence.

NEMA Enclosure Rack Rails


1418FS and HN4FS Series Enclosures



- Provides 19" or 24" mounting capability.
- Sold in pairs.
- Formed from 10 gauge steel.
- Drilled and tapped 10-32 to EIA spacing of 0.5" - 0.63" - 0.63" - 0.5".
- Compatible with **1418FS** and **HN4FS** enclosures.
- Finished in white.

Accessories

- 10-32 Mounting Hardware

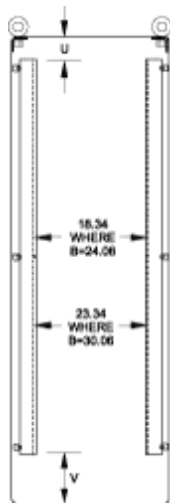

Part No.	Panel Description	Enclosure	Width	RU	Height Panel	U	V
1418TFHP	Full Height	60 x 24	19.00	28	49.00	3.78	7.78
1418THHP	Half Height			15	26.25	3.59	7.59
1418WFHP	Full Height	72 x 24	19.00	35	61.25	3.66	7.66
1418WHHP	Half Height			18	31.50	3.97	7.67
1418XFHP	Full Height	72 x 30	24.00	35	61.25	3.66	7.66
1418XHHP	Half Height			18	31.50	3.97	7.67
1418YYFHP	Full Height	90 x 24	19.00	45	78.75	3.91	7.91
1418YYHHP	Half Height			23	40.25	4.09	8.09

Tags: rack rail, 19", 24", 1418FS, HN4FS, freestanding, rackmount

Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1418TFHP](#) [1418YYFHP](#) [1418XFHP](#) [1418WHHP](#) [1418THHP](#) [1418YYHHP](#) [1418WFHP](#) [1418XHHP](#)