




Quality Products. Service Excellence.

Type 4 Mild Steel Two Door Floormount Enclosure 1422 N4 FM QT Series

Continuous Hinge Door with Quarter Turn

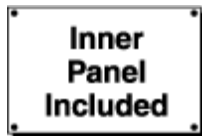

Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.

Standards

- UL 508A Type 3R, 4 and 12
- CSA Type 3R, 4 and 12
- Complies with
 - NEMA Type 3R, 4 12 and 13
 - IEC 60529, IP66

Construction

- Enclosures are formed steel - 12 gauge (60" high) or combination 10/12 gauge (72" high)
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Body stiffeners are provided in the larger enclosures for extra rigidity.
- Heavy duty lifting eyebolts are provided with reinforcing support angles.
- Center post is removable for easy installation of the inner panel.
- Formed lip on door and top of enclosure opening exclude flowing liquids and contaminants.
- Continuously hinged doors may be removed by pulling the stainless steel hinge pin.
- Doors are secured with quarter turn latches.
- Provision for padlocking.
- 12" floor stands are welded to the enclosure.
- Seamless poured-in place gasket.
- Provision for light kit mounting.
- A removable 10 gauge inner panel is included.
- Panel supports are provided for easy panel installation.
- Collar studs are provided for mounting inner panels.
- A bonding stud is provided on the door and a grounding stud is provided in the enclosure for each door.
- A literature pocket is provided for the inside of the door.

Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating.
- Removable white inner panel is finished in white powder coating.

Accessories

- Additional Inner Panels
- Barrier Kits for Type 4 Floormount
- Enclosure Stabilizers
- Window Kits
- General Accessories
- Door Stop Kit
- Drip Shield Kit
- Climate Control
- Lighting

**New and improved PDF part
drawing files with more detail
now available.**

Click part number in table below
to access PDF, DXF, and STEP files.

Part No.	Enclosure			Panel	
	H	W	D	H	W
1422N4B10FQT	60.13	48.06	10.69	56.00	44.00
1422N4D12FQT	60.13	60.06	12.69	56.00	56.00
1422N4E12FQT	72.13	60.06	12.69	68.00	56.00
1422N4F12FQT	72.13	72.06	12.69	68.00	68.00
1422N4F24FQT	72.13	72.06	24.69	68.00	68.00

Tags: 1422, floormount, two door, steel, Type 4, NEMA 4, pneumatic, hydraulic, instrument, inner panel, continuous hinge, quarter turn

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1422N4B10FQT](#) [1422N4D12FQT](#) [1422N4E12FQT](#) [1422N4F12FQT](#) [1422N4F24FQT](#)