




*Quality Products. Service Excellence.*

## Type 4X Stainless Steel Two Door Floormount Enclosure 1422 N4 QT SS

Series

Continuous Hinge Door with Quarter Turn

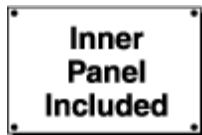

### Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.

### Standards

- UL 508A Type 3R, 4, 4X, and 12
- CSA Type 3R, 4, 4X, and 12
- Complies with
  - NEMA Type 3R, 4, 4X, 12 and 13
  - IEC 60529, IP66

### Construction

- Formed 12 gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Body stiffeners are provided in the larger enclosures for extra rigidity.
- Heavy duty stainless steel lifting eyebolts are provided with reinforcing support angles.
- Center post is removable for easy installation of the inner panel.
- Formed lip on door and top of enclosure opening exclude flowing liquids and contaminants.
- Continuously hinged doors may be removed by pulling the stainless steel hinge pin.
- Doors are secured with quarter turn latches.
- Provision for padlocking.
- 12" floor stands are welded to the enclosure.
- Seamless poured-in place gasket.
- Panel supports are provided for easy panel installation.
- Collar studs are provided for mounting inner panels.
- A bonding stud is provided on the door and a grounding stud is provided in the enclosure for each door.
- A literature pocket is provided.

### Finish

- Cover and enclosure are natural stainless steel with a smooth brushed finish.
- Removable 10 gauge inner panel is finished in white powder coating.

### Accessories

- Additional Inner Panels
- Barrier Kits for Type 4 Floormount
- Quarter Turn Inserts and Keys
- Climate Control
- General Accessories
- Door Stop Kit
- Drip Shield Kit
- Window Kits
- Lighting

**New and improved PDF part  
drawing files with more detail  
now available.**

Click part number in table below  
to access PDF, DXF, and STEP files.

304 S.S. Part No.	316 S.S. Part No.	Enclosure			Panel	
		H	W	D	H	W
1422N4SSB12FQT	1422N4S16B12FQT	60.13	48.06	12.69	56.00	44.00
1422N4SSD12FQT	1422N4S16D12FQT	60.13	60.06	12.69	56.00	56.00
1422N4SSE12FQT	1422N4S16E12FQT	72.13	60.06	12.69	68.00	56.00
1422N4SSF12FQT	1422N4S16F12FQT	72.13	72.06	12.69	68.00	68.00
1422N4SSF24FQT	1422N4S16F24FQT	72.13	72.06	24.69	68.00	68.00

Tags: 1422, floormount, two door, stainless steel, Type 4X, NEMA 4X, instrument, hydraulic, pneumatic, 304, 316, continuous hinge, quarter turn

Data subject to change without notice

© 2024. Hammond Manufacturing Ltd. All rights reserved.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1422N4S16B12FQT](#) [1422N4S16D12FQT](#) [1422N4S16E12FQT](#) [1422N4S16F12FQT](#) [1422N4S16F24FQT](#)  
[1422N4SSB12FQT](#) [1422N4SSD12FQT](#) [1422N4SSE12FQT](#) [1422N4SSF12FQT](#) [1422N4SSF24FQT](#)